



Trac-Master® Classics Series

Timeless track lighting solutions

JUNO®



Trac-Master® Classics - Stylish Familiarity

Juno Classics are benchmark fixture designs that incorporate timeless shapes and themes. These simple yet elegant fixtures provide economical track lighting solutions in extremely practical, functional packages. Comprised mainly of gimbal rings, cylinders, and universals, Juno design Classics are offered in a variety of


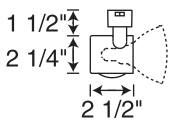
finishes to suit most any décor. Familiar lines and traditional shapes create levels of visual comfort typically not encountered in more contemporary styles. Primarily designed for PAR and R/BR lamps, these uncomplicated fixture styles offer unpretentious aesthetics that blend well in any environment.

Close-Ups


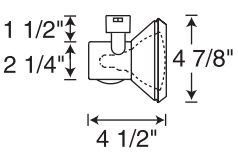
Close-Ups

As the name implies, this compact, stylish lampholder hugs close to the track for minimum intrusion into a space. The softly sculpted back detail and metal shades are welcome design refinements for many interiors.


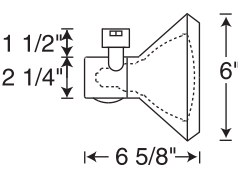
PAR30 - Open

	Catalog # T230 WH	Finish White	Lamp 75W max. PAR30	Dimensions 
---	-----------------------------	------------------------	-------------------------------	--

PAR30 - Enclosed

	Catalog # T231 WH	Finish White	Lamp 75W max. PAR30	Dimensions 
---	-----------------------------	------------------------	-------------------------------	--

PAR38 - Enclosed

	Catalog # T239 WH T239 BL	Finish White Black	Lamp 120W max. PAR38	Dimensions 
--	--	---------------------------------	--------------------------------	---

The product and system may be covered by the following patents: U.S. Patent D376,026; Canada Patent 79,733

Open Back Gimbals

Open Back Gimbals

Gimbal rings are ever popular due to their long-standing use as an economical, general-purpose track lampholder.




Catalog #
T368 WH

Finish
White

Lamp
150W max. PAR38

Dimensions

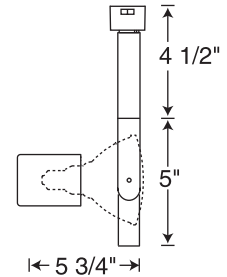


Accessories

For Fixtures	T368
Color Filters	CGF 469
Dichroic Filters	DGF 469
Diffusion Lens	DIFF 469
Uniformity Lens	SOLITE 469
UV Filter	UVF 469
Prismatic Spread Lens	PRISM 469
Linear Spread Lens	LSPREAD 469
Hexcell Louver	HCLBL 469
Snoot	SNOOTBL 469

Front Lamping Gimbals

Front Lamping Gimbals

A Juno innovation, the front-loading gimbal ring combines the practicality, versatility, and economy of traditional gimbal ring track fixtures with a fixed socket housing to allow simplified front relamping.

	Catalog # T687 BL	Finish Black	Lamp 50W max. PAR20	Dimensions 
	Catalog # T689 WH T689 BL	Finish White Black	Lamp 75W max. PAR30	Dimensions 
	Catalog # T690 WH T690 BL T690 SL	Finish White Black Silver	Lamp 250W max. PAR38	Dimensions 

Note: T690 BL is available with TEK, GTYPE, HTYPE and LTYPE Alternate Mounting Adapters – see specification sheet for details.

Universals

Universals


These economical, universal lampholders accept a wide range of wattages and sizes of popular halogen PAR and incandescent R/BR lamps.



Catalog #
T308 WH
T308 BL

Finish
 White
 Black


Lamp
 50W max. R20/
 50W max. PAR20/
 85W max. BR30/
 75W max. PAR30/
 120W max. BR40/
 150W max. PAR38

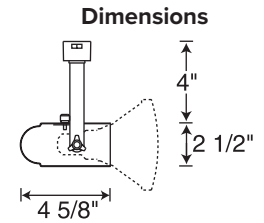

Catalog #
T620 WH
T620 BL

Finish
 White
 Black


Lamp
 50W max. R20/
 50W max. PAR20/
 85W max. BR30/
 75W max. PAR30/
 120W max. BR40/
 150W max. PAR38

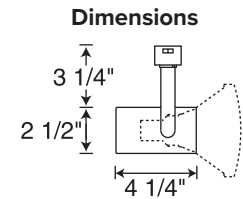

Catalog #
T691 WH
T691 BL
T691 NAT

Finish
 White
 Black
 Natural

Lamp
 60W max. PAR16/
 50W max. PAR20/
 75W max. PAR30/
 150W max. PAR38

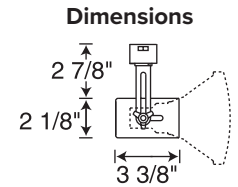

Notes:

T691 WH is available with GTYPE, HTYPE and LTYPE Alternate Mounting Adapters – see specification sheet for details.

The Natural (NAT) finish is merely a raw finish with a clear protective coating applied—inconsistencies, scratches, and minor processing marks are part of the unique aesthetic created by this process and should be expected.

Flat Black Cylinders

Flat Back Cylinders

These long-standing traditional lampholders accept both halogen PAR and incandescent R/BR lamps and provide deep lamp shielding.

	Catalog # T313 WHB WH T313 BLB BL	Finish White/White Baffle Black/Black Baffle	Lamp 50W max. R20/ 50W max. PAR20	Dimensions 
	Catalog # T315 BLB BL	Finish Black/Black Baffle	Lamp 75W max. BR30/ 75W max. PAR30L	Dimensions 

Accessories

For Fixtures	T313	T315
Accessory Holder	T560BL	-
Color Filters	CGF 375*	CGF 469*
Dichroic Filters	DGF 375*	DGF 469*
Diffusion Lens	DIFF 375*	DIFF 469*
Uniformity Lens	SOLITE 375*	SOLITE 469*
UV Filter	UVF 375*	UVF 469*
Prismatic Spread Lens	PRISM 375*	PRISM 469*
Linear Spread Lens	LSPREAD 375*	LSPREAD 469*
Hexcell Louver	HCLBL 375*	HCLBL 469*
Cube Cell Louver	CCLBL 375*	-
Snoot	SNOOTBL 375*	SNOOTBL 469*
Barn Doors	T71BL 375	T72BL 469

* Filters, lenses, and louver require accessory holder or barn doors for installation.



Juno