


POWERHOLD™ Receptacle

15 and 20 Amp, 125V
Duplex and Decorator

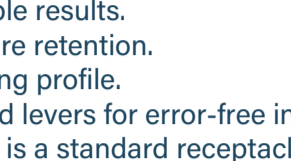

CATALOG NUMBERS:
TR15DV, TR20DV, TR26242DV,
TR26342DV



Made in China

Description


- The PowerHold receptacle maximizes contractor productivity, reduces errors and enhances profitability while delivering faster, more reliable results.
- Superior wire retention.
- Space-saving profile.
- Color-coded levers for error-free installation.
- This device is a standard receptacle with the capacity of making the installation process safe, fast and easy. With no exposed live components.
- The device has a dual mechanical shutter system to help prevent insertion of foreign objects.
- Auto-ground clip to assure positive ground
- Easily accessed break-off tab for fast and easy split-circuit wiring.
- Corrosion-resistant plated steel strap.
- Built-in strip gauge.

Features

The colored levers snap shut to terminate the wires.

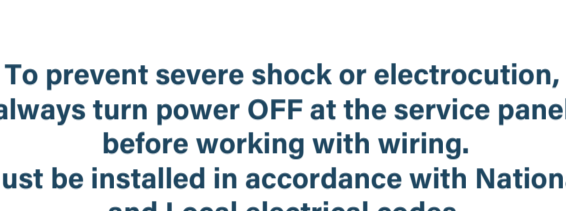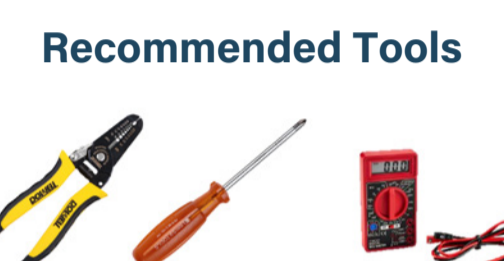

Recommended Tools

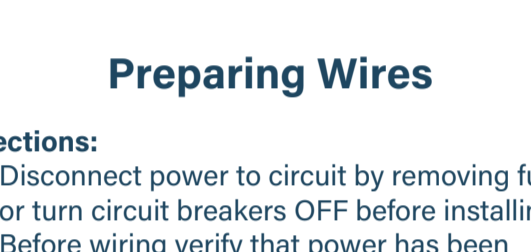

To prevent severe shock or electrocution, always turn power OFF at the service panel before working with wiring.


Must be installed in accordance with National and Local electrical codes.

WARNING: IMPROPER WIRING OF ANY ELECTRICAL DEVICE CAN CAUSE SERIOUS INJURY OR DEATH. THESE WIRING DEVICES SHOULD BE INSTALLED BY AN ELECTRICIAN OR OTHER QUALIFIED PERSON.

Preparing Wires

Directions:


1. Disconnect power to circuit by removing fuse or turn circuit breakers OFF before installing.
2. Before wiring verify that power has been removed by testing with a circuit tester at the outlet box.
3. To replace existing device, remove wall plate and pull device from box. If new installation, skip to step 5.
4. Label wires connected to existing device; wire colors might not be the same as the levers so make sure you have them properly identified.
5. Disconnect existing device.
6. Strip each wire in the wall box, removing the insulation and exposing 0.42" of bare wire, use strip gauge to verify. Use #10 - #14 AWG solid or stranded wire. Make sure the ends are straight.

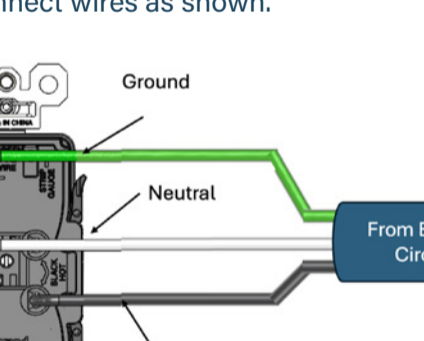

Wiring the Device

Directions:


1. Verify that you have your wallbox wires identified, Line (black) wire, Neutral (white) wire and a Ground (Bare copper or green) wire.
2. Fully open levers as shown, line and neutral levers open horizontally and ground lever opens vertically.
3. Insert the proper wire per lever color fully into the wire hole.
4. Fully close the lever.
5. Make sure the wire is fully inserted, and no bare wire is exposed. If required, re-open the lever and adjust wire.

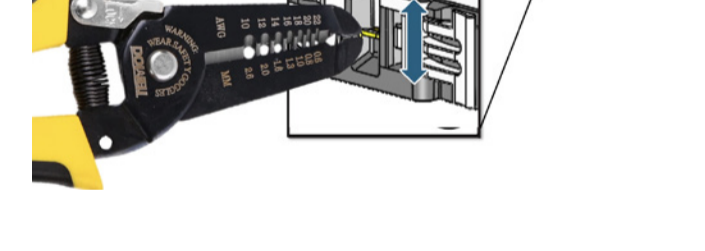

Common Feed Wiring

Directions:

1. Connect wires as shown.

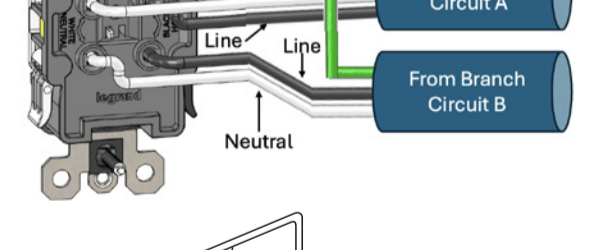


Split Circuit Wiring



Directions:

1. Break off split circuit tab by grabbing it and moving up and down until it breaks.

Note: If required, both line and neutral sides have a split circuit tab.

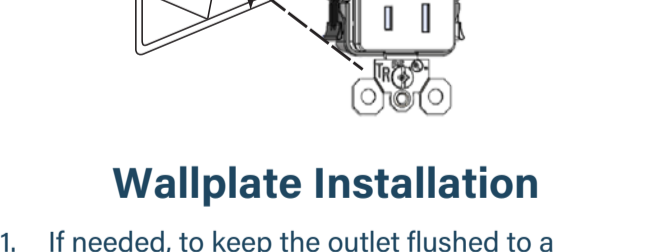


2. Connect the wires as shown.

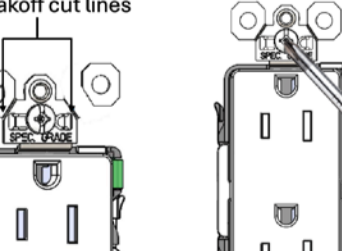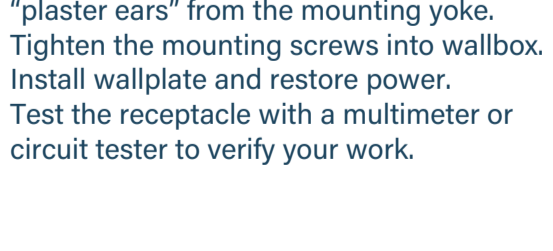

Wallplate Installation

1. If needed, to keep the outlet flushed to a surface of the wall you can remove the "plaster ears" from the mounting yoke.
2. Tighten the mounting screws into wallbox.
3. Install wallplate and restore power.
4. Test the receptacle with a multimeter or circuit tester to verify your work.

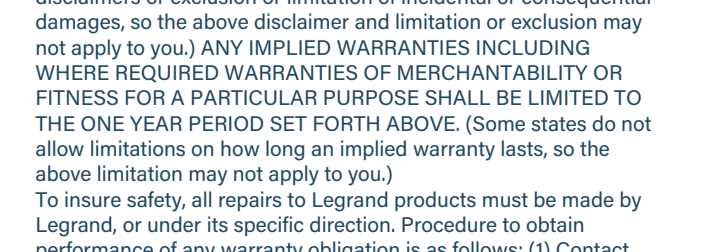

LIMITED ONE YEAR WARRANTY

Legrand will remedy any defect in workmanship or material in Legrand products which may develop under proper and normal use within one year from date of purchase by a consumer:

(1) by repair or replacement, or, at Legrand's option, (2) by return of an amount equal to consumer's purchase price. Such remedy is IN LIEU OF ANY AND ALL EXPRESSED OR IMPLIED WARRANTIES OF MERCHANTABILITY OR FITNESS FOR A PARTICULAR PURPOSE. Such remedy by Legrand does not include or cover cost of labor for removal or reinstallation of the product. ALL OTHER FURTHER ELEMENTS OF DAMAGE (INCIDENTAL OR CONSEQUENTIAL DAMAGES) FOR BREACH OF ANY AND ALL EXPRESSED OR IMPLIED WARRANTIES INCLUDING WARRANTIES OF MERCHANTABILITY OR FITNESS FOR A PARTICULAR PURPOSE ARE EXCLUDED HEREBY. (Some states do not allow disclaimers or exclusion or limitation of incidental or consequential damages, so the above disclaimer and limitation or exclusion may not apply to you.) ANY IMPLIED WARRANTIES INCLUDING WHERE REQUIRED WARRANTIES OF MERCHANTABILITY OR FITNESS FOR A PARTICULAR PURPOSE SHALL BE LIMITED TO THE ONE YEAR PERIOD SET FORTH ABOVE. (Some states do not allow limitations on how long an implied warranty lasts, so the above limitation may not apply to you.)

To insure safety, all repairs to Legrand products must be made by Legrand, or its repairers in its specific direction. Procedure to obtain performance of any warranty obligation is as follows: (1) Contact Legrand, Syracuse, New York 13221, for instructions concerning return or repair; (2) return the product to Legrand, postage paid, with your name and address and a written description of the installation or use of the Legrand product, and the observed defects or failure to operate, or other claimed basis for dissatisfaction. This warranty gives you specific legal rights and you may also have other rights which vary from state to state.