

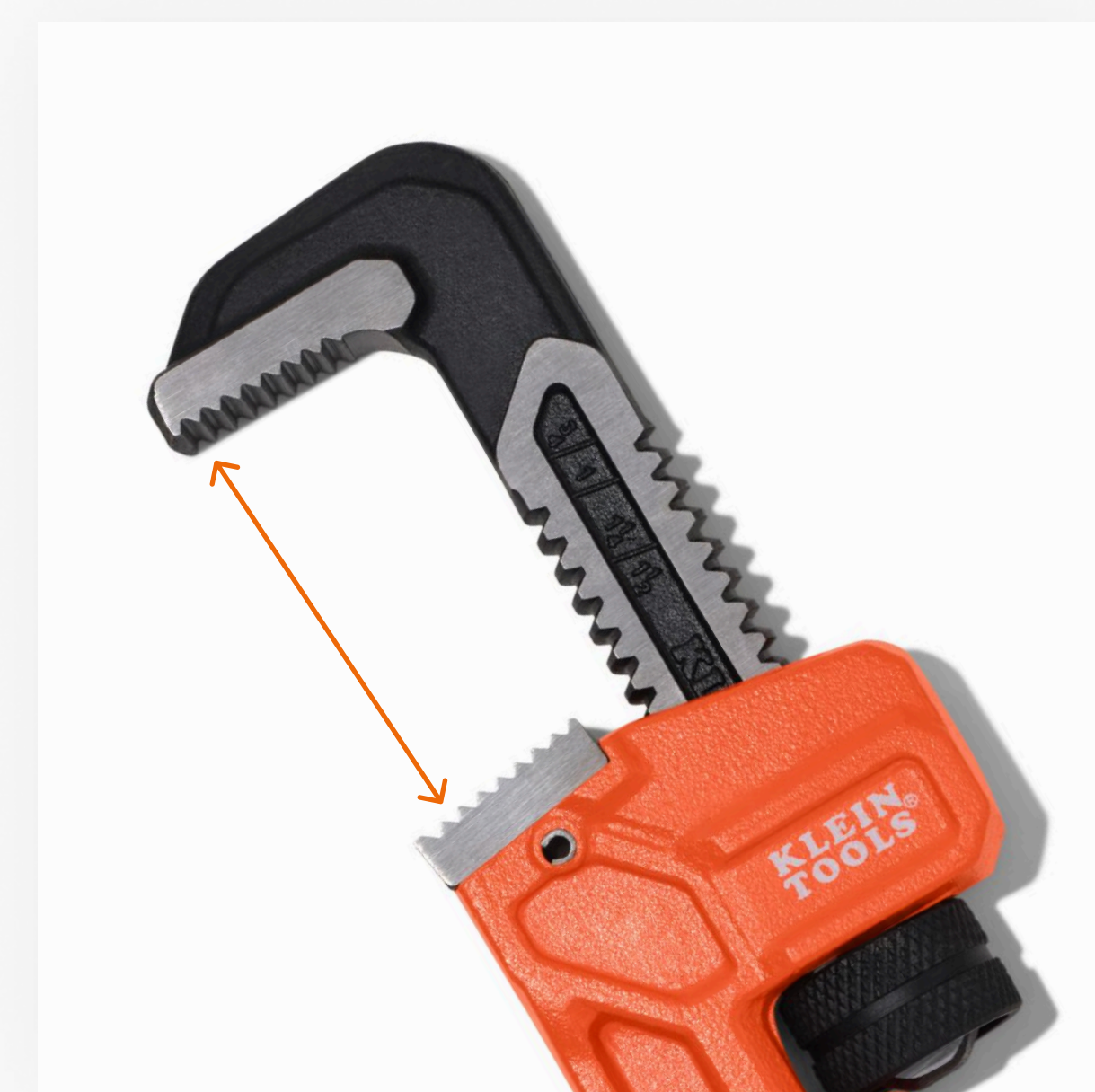


Cast Iron Pipe Wrench

Heavy Duty Performance, Lightweight Construction

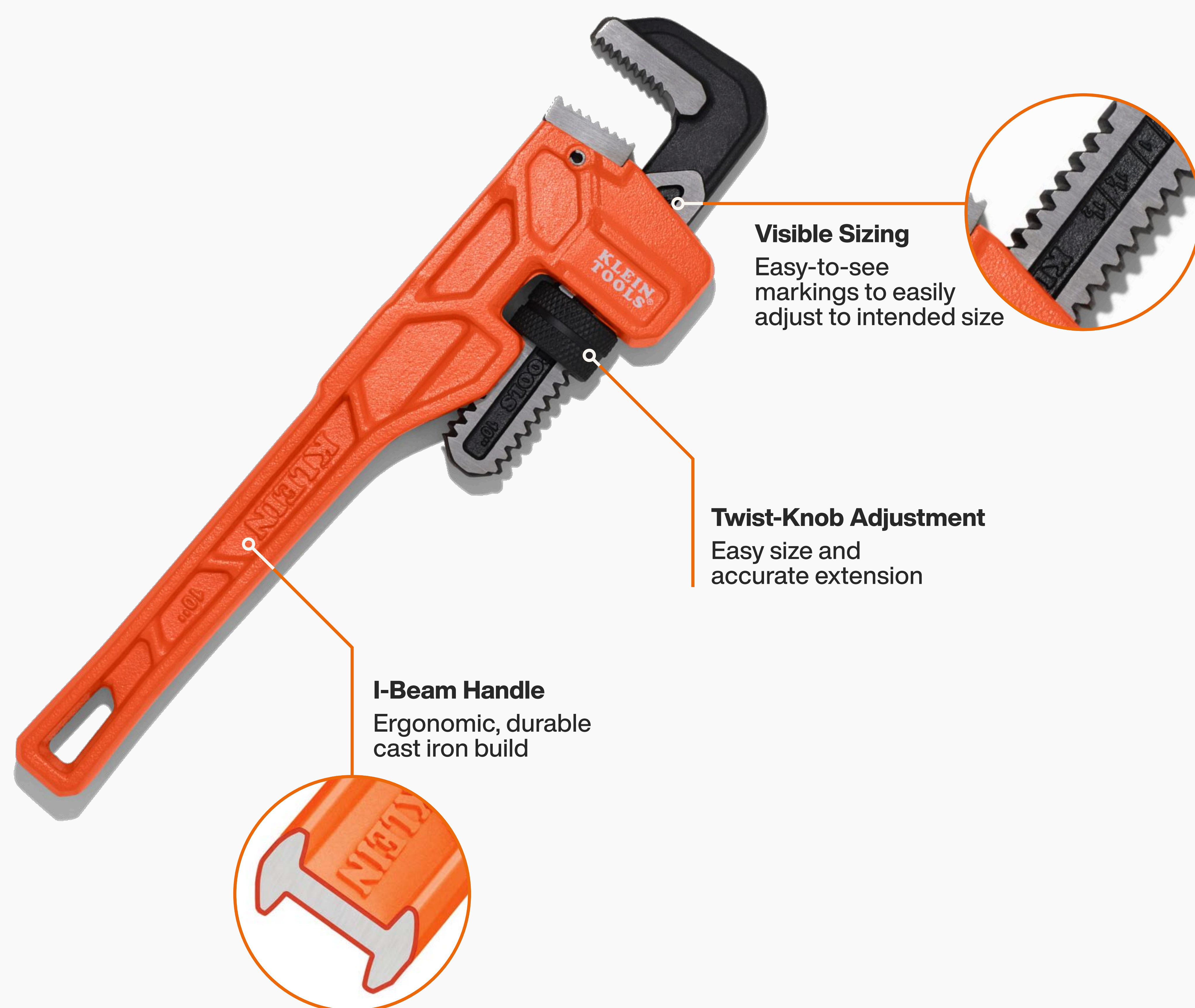

Extendable Jaw
Adjustable jaw fits many sizes of pipes

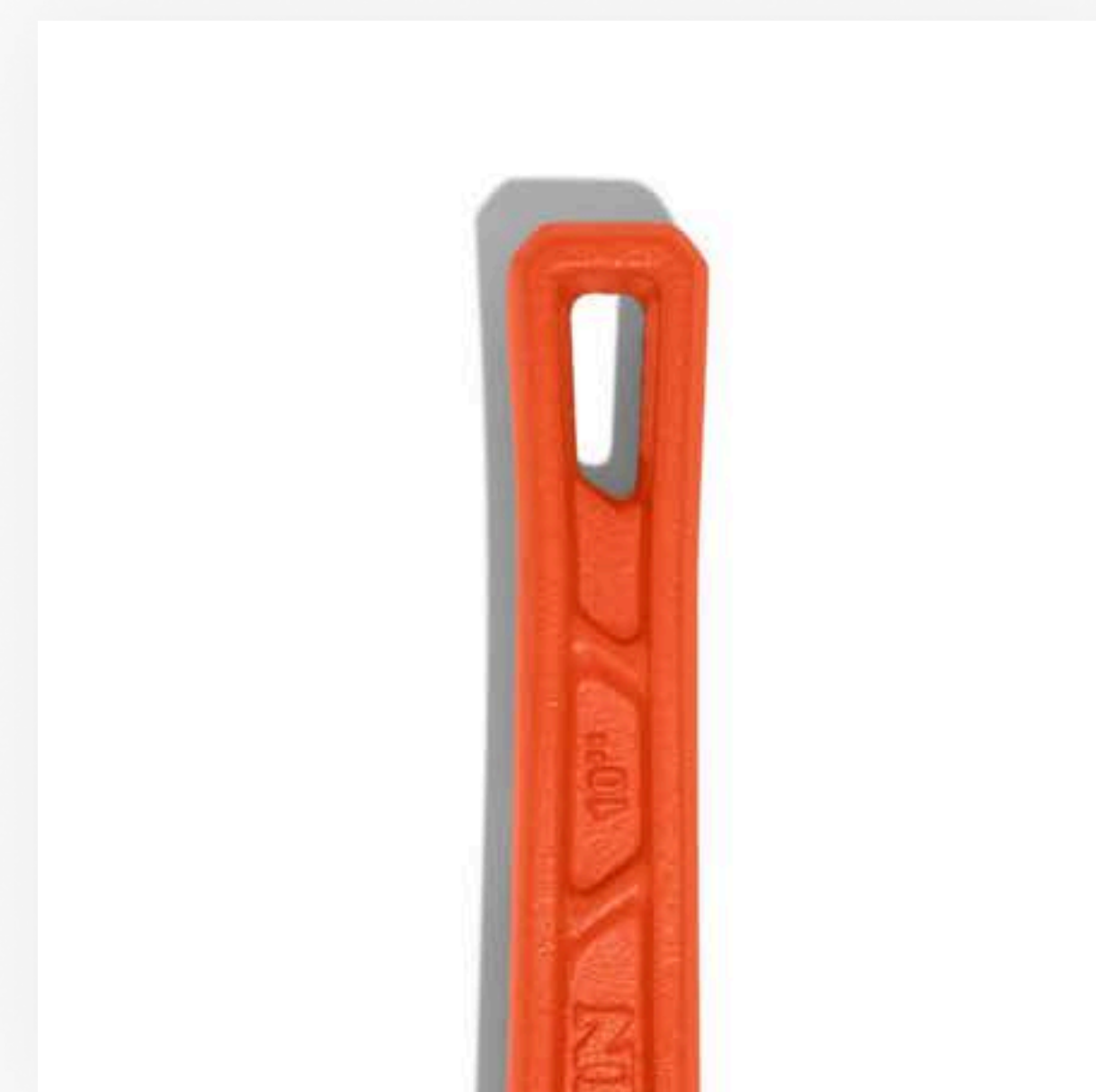

Hang Hole
Secure storage when not in use



No-Slip Grip
Optimized jaw design for high-torque application

68210
10" Cast Iron Pipe Wrench



68227
14" Cast Iron Pipe Wrench



68228
18" Cast Iron Pipe Wrench



Cat. No.	UPC	Description	Jaw Capacity	Special Features	Length	Weight
68210	0-92644-68210-0	10" Cast Iron Pipe Wrench	1 1/2" (4 cm)	I-Beam Handle; Hang Hole; Adjustable Jaw	10" (25 cm)	2.0lb (898 g)
68227	0-92644-68227-8	14" Cast Iron Pipe Wrench	2" (5.1 cm)	I-Beam Handle; Hang Hole; Adjustable Jaw	14" (36 cm)	2.9lb (1.3 kg)
68228	0-92644-68228-5	18" Cast Iron Pipe Wrench	2.5" (6.4 cm)	I-Beam Handle; Hang Hole; Adjustable Jaw	18" (46 cm)	5.2lb (2.4 kg)

⚠ Visit www.kleintools.com for warnings.

KLEIN TOOLS 

See our complete line of pliers. www.kleintools.com

© 2026 Klein Tools, Inc. • Lincolnshire, IL 60069 • Rev. 02/26 C