

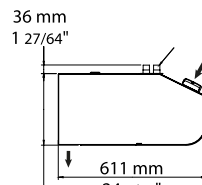


Surface - Montage horizontal Surface - Horizontal mounting

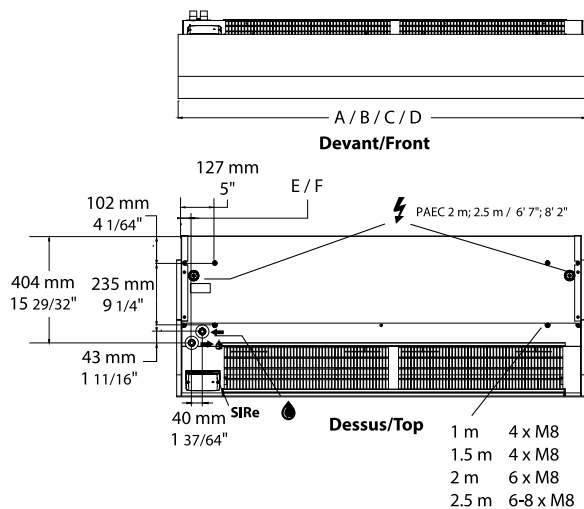


	mm	po/in.	Type
A	1039	40 29/32	PAEC4010x
B	1549	60 63/64	PAEC4015x
C	2039	80 9/32	PAEC4020x
D	2549	100 23/64	PAEC4025x
E	40	1 37/64	PAEC4010/15/20x
F	39	1 17/32	PAEC4025x
G	1572	61 57/64	PAEC4015x
H	2062	81 3/16	PAEC4020x
I	2572	101 17/64	PAEC4025x
J	1515	59 41/64	PAEC4015x
K	2004	78 57/64	PAEC4020x
L	2515	99 1/64	PAEC4025x

Surface - Montage vertical Surface - Vertical mounting

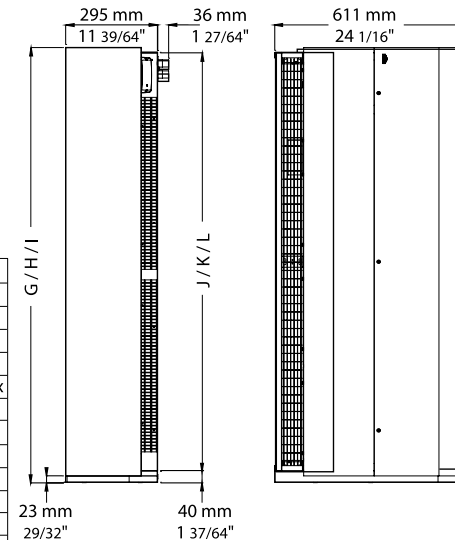

Encastré/Recessed

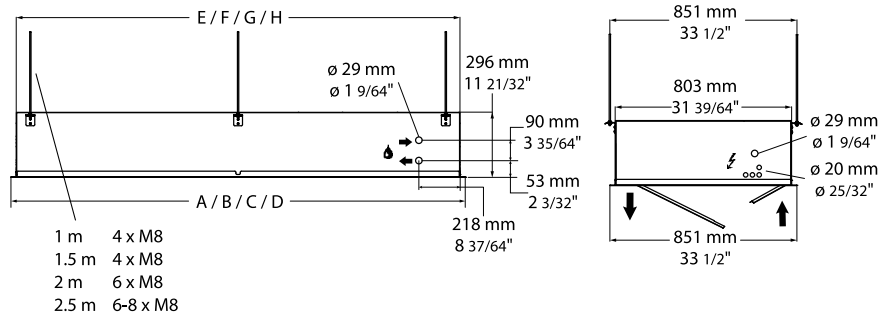

	mm	po/in.	Type
A	1067	42 1/64	AREC4010x
B	1577	62 3/32	AREC4015x
C	2067	81 3/8	AREC4020x
D	2579	101 17/32	AREC4025x
E	1020	40 5/32	AREC4010x
F	1520	59 27/32	AREC4015x
G	2020	79 17/32	AREC4020x
H	2520	99 7/32	AREC4025x