



# BX, Flex Connectors

## 90° - Squeeze Type - Zinc



### Features

- Squeeze type

### Applications


- Indoor use only
- In a dry location, use to connect flexible metallic conduit and steel AC cable to a steel outlet box, load center or other metal enclosure
- The 3/8" can also be used with steel and aluminum MC cable
- 3/8" size fits 1/2" knockout

### Standard Material

- Zinc die cast
- Zinc plated steel strap

### Certification

- UL File #: E224953

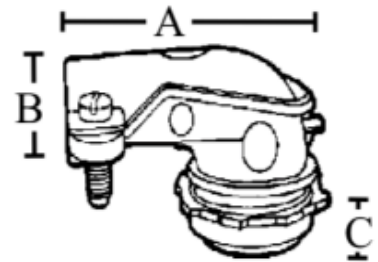

Catalog Number	UPC	Conduit Size	Box Qty	Ship Case	Weight Box Qty	Inches			Screws
						A	B	C	
100Z	16089	3/8" 1/2" KO	25	250	2.3	1.74	.43 - .72	0.37	2
101Z	16090	1/2"	25	100	3.5	2.11	.64 - 1.03	0.40	2
102Z	16091	3/4"	10	50	2.0	2.40	.76 - 1.15	0.40	2
103Z	16092	1"	25	---	9.5	2.87	1.09 - 1.73	0.54	2
104Z	16093	1-1/4"	25	---	12.5	4	1.34 - 1.97	0.64	2
105Z	16094	1-1/2"	5	---	5.0	6	1.65 - 2.61	0.75	2
106Z	16095	2"	5	---	6.0	6	1.54 - 2.54	0.74	2
107Z	16096	2-1/2"	5	---	18.0	7.187	2.45 - 2.98	0.875	4
108Z	16097	3"	5	---	22.5	7.875	2.93 - 3.45	1.031	4
109Z	16098	3-1/2"	1	---	9.0	9.40	3.28 - 3.95	1.031	4
110Z	16099	4"	1	---	10.0	10.20	3.68 - 4.43	1.031	4

### Nesco Inc.

1039 Cardiff Blvd., Mississauga, ON L5S 1P4  
 TF: (866) 466-3726 Tel: (905) 793-2218 Fax: (905) 793-2268  
 www.nescocanada.com