


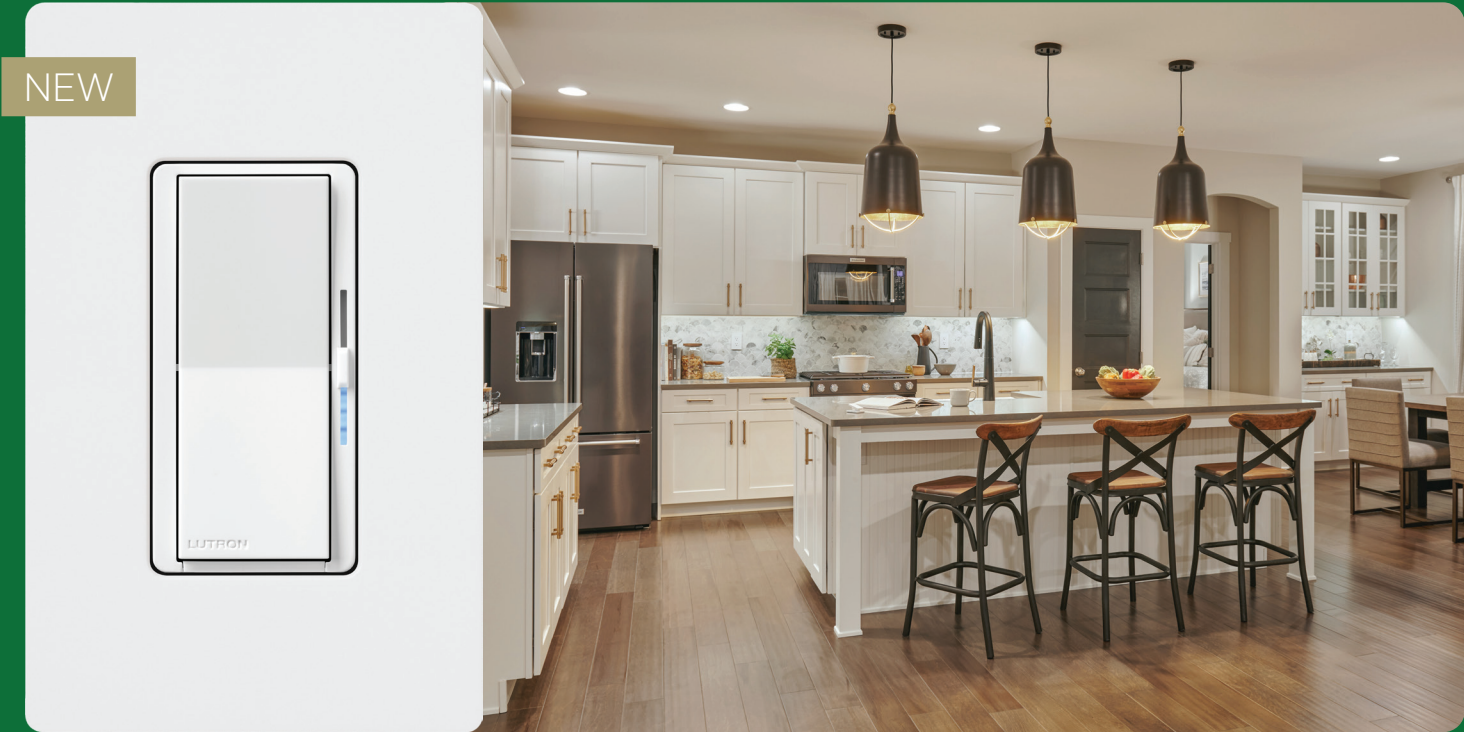

New Diva dimmer – LED+ Pro Max model

Handle the Surprises. No Extra Trips.

Keep Lutron Diva dimmer – LED+ Pro Max model on the truck for maximum power and versatility with LED, ELV, MLV, and INC/HAL lighting loads.




DV-PRO-WH

Diva dimmer – LED+ Pro Max model

Model	DV-PRO-XX
Description	Diva dimmer – LED+ Pro Max model
Rating/Load Type	Phase selectable – 250W LED, 500W ELV, 400VA MLV, 500W INC/HAL
Neutral Required	No neutral wire required for LED/INC/HAL Neutral wire required for ELV/MLV
3-way/Multi-location Options	Accessory switch ST-AS-XX (gloss) for 3-way/multi-location, or any traditional mechanical switch for 3-way only
Maximum Number of Companions	9
Identical Companion Appearance	No
Identical Companion Functionality	No - accessory locations are for switching only (Press for on/off).
Dim from All Locations	No

Still have questions? Call Lutron's 24/7 lifetime technical support at 1-844-LUTRON1.

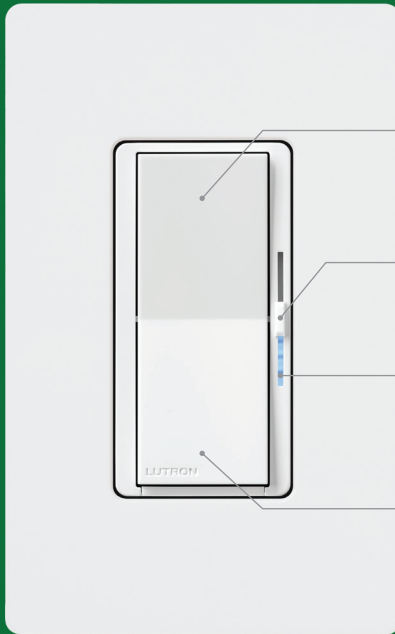

- Tap once to turn on to slider preset; double tap for full on
- Slide to adjust preset and light level
- Soft-glow light bar demonstrates light level
- Tap once for fade-to-off; press and hold for delayed fade-to-off



- Multi-Location**
- Lighting Load**
120 V Hot/Line
- Neutral**
LED/INC/HAL
(no neutral required)
ELV/MLV (neutral required)
- Ground**

The Gold Standard in Dimmers. No Flicker. No Buzz. No Compromise.

The Diva dimmer – LED+ Pro Max model simplifies your projects with one dependable solution for almost any lighting challenge. Unmatched reliability and performance to get the job done.



PHASE SELECTABLE
Use with forward or reverse phase dimming



ELV 500 W
Tape light for under cabinet and toe kick



LED 250 W | INC/HAL 500 W
Dimmable LED bulbs and downlights



MLV 400 VA
Track lights and fixtures for accent lighting

*With product registration.
5-year warranty without registration.

Colors

Gloss Finishes

