

GOOSENECK

Outdoor LED Wall Light

OS140-CCT

SPECIFICATION SHEET



SPECIFICATIONS



Housing details

Diecast aluminum, corrosion-resistant housing with black powder paint for lasting durability.

Fixture is fully sealed to keep out moisture and dirt (IP65).

Adjustable Wattage (20W, 30W, 40W)

3CCT Selectable (3K,4K,5K)

Photocell – Dusk/Dawn (Override possible by covering with the provided cap)

Installation

Hardware included

Adjustable Set Angle

Wet locations listed (IP65) for outdoor installations.

Can be mounted to a junction box or on a wall.

Electrical

Easily connected to a 120-277V power supply. 0-10V dimmable.

Selectable Color Temperature (3000K, 4000K, 5000K)

Rated for outdoor installations, -20°C (4°F) minimum starting ambient temperature

Listings: This product is cETLus listed to U.S and Canadian safety standards for wet locations.

DLC Premium Listed

Selectable color temperature	3K / 4K / 5K
Lumen output	2400 lumens 3600 lumens 4800 lumens
Wattage	20W 30W 40W
Voltage	120 – 277V
Dimmable	Yes (0-10V)
CRI	80+
IP rating	IP65
Photocell	YES
LED life	50,000 hours
Warranty	5 years


Mounting Options

This fixture is not designed to be mounted on the ground. It is intended to be wall mounted at a height of 4 feet (1.22m) or higher using the provided hardware.

FINISHES



DIMENSIONS

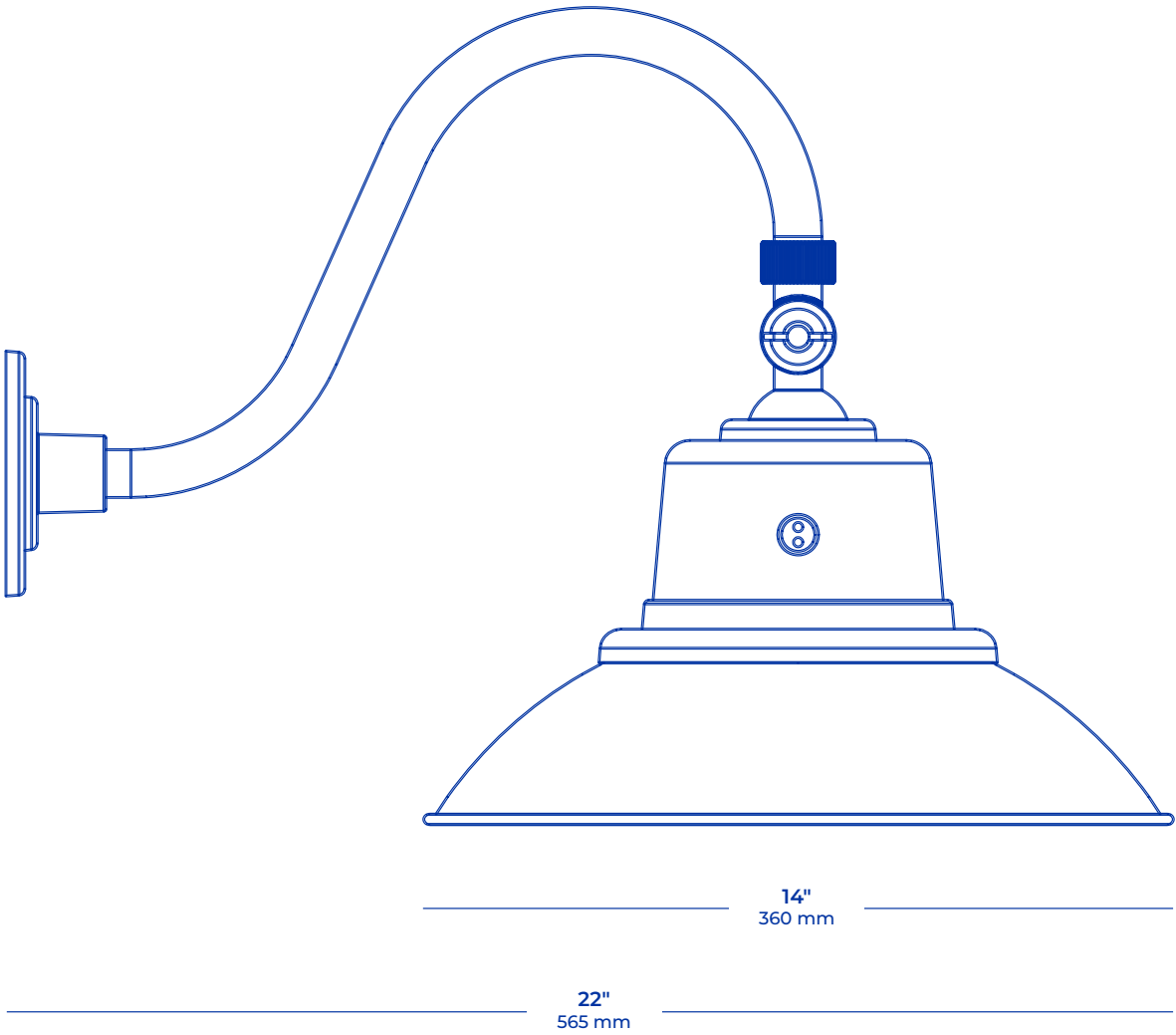

APPLICATIONS

The Gooseneck Outdoor Wall Light offers general and security lighting for outdoor residential and/or commercial applications. It's powerful lumen output, 3 selectable wattage options, 3CCT selectable color temperature, and dusk / dawn photocell option proves ideal for building facades, awnings, barn lighting, signage, and plenty more outdoor applications

RATINGS & CERTIFICATIONS



Wet locations
rated



Dimmable
(0-10V)

ORDERING GUIDE

Series	Color temperature	CRI	Wattage	Finish
OS140	3CCT 3000K / 4000K / 5000K	80+	40W	BK Back

Note: Configure product using **BOLD** options: Ex: **OS140-CCT-BK**