


SGH | SPIDER™

CEILING FAN HEATER



SPIDER™

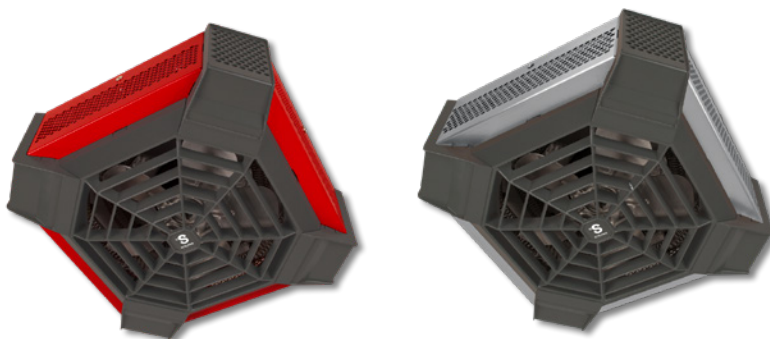

GET CAUGHT UP IN ITS COMFORT!

This stylish ceiling fan heater will be the highlight of your garage! The SPIDER ceiling fan heater combines optimum performance, instant heat and a low noise level, all this in a distinctive design.

INNOVATIVE AND UNIQUE DESIGN

DESIGNED SPECIFICALLY FOR RESIDENTIAL GARAGES

CEILING INSTALLATION FREES UP FLOOR AND WALL SPACE

COLOURS

- **standard:** red
- **luxury finish:** stainless steel (see price list)

FINISH

- polyester powdercoat or stainless steel

MANUFACTURING

- 22-gauge smooth steel housing
- quiet helicoidal fan
- thermal protection with automatic reset
- closed and permanently lubricated motor

ELEMENT

- nichrome element producing instant heat

CONTROL

- wall thermostat (not included) – the use of an electronic thermostat is strongly recommended

INSTALLATION


- ceiling surface mounted with bracket
- from adjacent walls at a minimum of 12 in. (305 mm)
- from floor at a minimum of 8 ft. (2.4 m) and a maximum of 10 ft. (3 m)

WARRANTY

- five years

IDEAL FOR:

garage, workshop

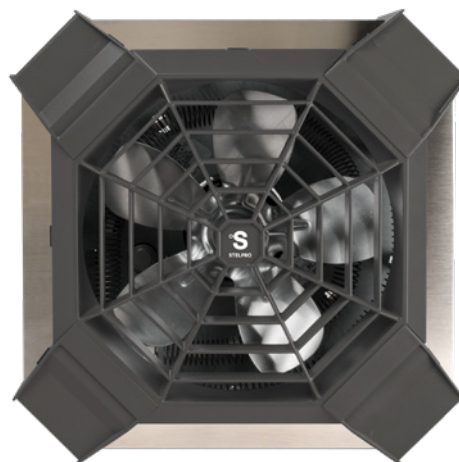

°STELPRO

°STELPRO reserves the right to modify descriptions, manufacturing specifications or prices without prior notice. No returns accepted on optional-colour products. For all the latest models and prices, please refer to our website at www.stelpro.com.



FC_SGH_EN_301018



TECHNICAL SPECIFICATIONS

PRODUCT	POWER	VOLTAGE	COLOUR	HEAT RISE		WEIGHT		PRICE
CODE	WATTS	VOLTS		°C	°F	KG	LB	
SGH4002R	4000/3000	240/208	RED	46	83	4.5	10	335.00
SGH4002SS	4000/3000	240/208	STAINLESS STEEL	46	83	4.5	10	435.00

TECHNICAL DRAWINGS

