

# SHDL

## HAND DRYER



### ONE MODEL, TWO VERSIONS

The SHDL series hand dryer is constructed with a one-piece, ultra-resistant Lexan cover and is surface mounted. It is available either fully automatic or with a push button.

#### STARTS AND STOPS AUTOMATICALLY (SHDLAS MODEL)

#### PUSH BUTTON STARTS AND STOPS MANUALLY (SHDLPB MODEL)

#### COLOUR

- white

#### MANUFACTURING

- shell is a one-piece mold of Lexan 940
- secured to a zinc alloy wall bracket with two chrome-plated, tamper-proof bolts
- chrome-plated, die-cast zinc turbine forces air
- tamper-proof vent, preventing the insertion of foreign objects

#### SOUND LEVEL

- 72 dBA

#### ELEMENT

- nichrome

#### CONTROL

- SHDLAS model - an infrared optical sensor located next to the air outlet activates the hand dryer
- a 90-second lockout feature is activated if hands are not removed before this time
- SHDLPB model - push button start
- built-in 30-second sealed electronic timer


#### INSTALLATION

- wall mounted

#### WARRANTY

- five years, \*three years on electronic components

### TECHNICAL DRAWINGS

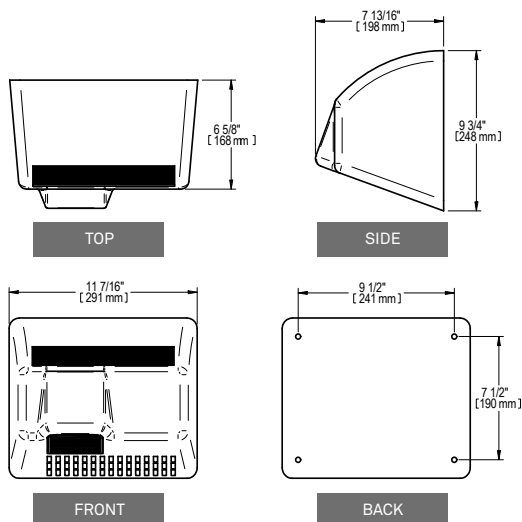

| IDEAL FOR                        | ENERGY SAVINGS | AIR SPEED OR AIR FLOW | HEATING POWER | NOISE LEVEL | DRYING TIME |
|----------------------------------|----------------|-----------------------|---------------|-------------|-------------|
| libraries, restaurants and cafés | ---            |                       |               |             |             |

### TECHNICAL SPECIFICATIONS

| PRODUCT  | POWER | VOLTAGE | AMPERAGE | WEIGHT |    | PRIX   |
|----------|-------|---------|----------|--------|----|--------|
| CODE*    | WATTS | VOLTS   | AMPERES  | KG     | LB |        |
| SHDLAS1W | 2000  | 120     | 20       | 9.0    | 20 | 541.00 |
| SHDLAS8W | 2000  | 208     | 11       | 9.0    | 20 | 541.00 |
| SHDLAS2W | 2000  | 240     | 11       | 9.0    | 20 | 541.00 |
| SHDLPB1W | 2000  | 120     | 20       | 8.1    | 18 | 472.00 |
| SHDLPB8W | 2000  | 208     | 11       | 8.1    | 18 | 472.00 |
| SHDLPB2W | 2000  | 240     | 11       | 8.1    | 18 | 472.00 |

### RECOMMENDED INSTALLATION HEIGHTS\*

| MEN             | WOMEN           | TEENAGERS      | CHILDREN       | HANDICAPPED    |
|-----------------|-----------------|----------------|----------------|----------------|
| 43 in. (109 cm) | 41 in. (104 cm) | 39 in. (99 cm) | 33 in. (84 cm) | 35 in. (89 cm) |

\*Distance between floor and bottom of hand dryer

**°STELPRO**

°STELPRO reserves the right to modify descriptions, manufacturing specifications or prices without prior notice. No returns accepted on optional-colour products. For all the latest models and prices, please refer to our website at [www.stelpro.com](http://www.stelpro.com).



FC\_SHDL\_EN\_311018