

# STE252NP

## ELECTRONIC THERMOSTAT – SINGLE PROGRAMMING

2500 W



### SMALL, PRACTICAL AND EFFICIENT!

The °STELPRO STE252NP single programming electronic thermostat is the thermostat of choice if your capacity requirement doesn't exceed 2500 W. It can control electronic convectors, electric baseboards and other heating units (including forced-air units) with precision. Good for small- and medium-sized rooms such as living rooms, kitchens, bedrooms and bathrooms.



**SIMPLE TO USE  
AND INSTALL**



**DISCREET AND COMPACT**



**INCREASED SAVINGS  
AND COMFORT**  
INCOMPARABLE ACCURACY



**BACKLIT SCREEN**  
CAN BE USED AS A NIGHTLIGHT



**ELECTRICITY SAVINGS**  
ENERGY SAVINGS OF 10-15%  
DEPENDING ON USE\*

#### COLOUR

- white

#### FINISH

- molded plastic

#### WATTAGE AND VOLTAGE

- 150 W to 1250 W @ 120 V
- 260 W to 2160 W @ 208 V
- 300 W to 2500 W @ 240 V

#### CONTROL

- two- or four-wire connection
- acts like a programmable thermostat by automatically lowering the temperature once per 24-hour period (Single programming mode)
- compatible with forced-air units (Fan mode)
- frost-free warning
- lock option at a maximum temperature setpoint (Security mode)
- display in Celsius or Fahrenheit

#### ACCURACY

- accurate ambient temperature control of  $\pm 0.5$  °C (1°F)
- CSA C828-13
- temperature sensing with thermistor

#### TEMPERATURE RANGE

- 3 to 30 °C (37 to 86 °F)

#### WARRANTY

- three years
- \* independent study

**°STELPRO**


°STELPRO reserves the right to modify descriptions, manufacturing specifications or prices without prior notice. No returns accepted on optional-colour products. For all the latest models and prices, please refer to our website at [www.stelpro.com](http://www.stelpro.com).



FC\_STE252NP\_EN\_031218



WALL SUPPORT (INCLUDED)

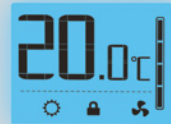

BACKLIT SCREEN  
CAN BE USED AS A NIGHTLIGHT

## TECHNICAL SPECIFICATIONS

PRODUCT	WATTS		VOLTAGE	AMPERAGE	FREQUENCY	PACKAGING	UNIT PRICE
CODE	MINIMUM	MAXIMUM	VOLTS	AMPERES	HZ		
<b>STE252NPWB+</b>	150/260/300	1250/2160/2500	120/208/240	10.4	50/60	BOX	<b>32.00</b>

Dimensions: 3 11/16 in. (94 mm) wide, 4 7/8 in. (124 mm) high and 1 1/8 in. (29 mm) deep

\*STELPRO reserves the right to modify descriptions, manufacturing specifications or prices without prior notice. No returns accepted on optional-colour products. For all the latest models and prices, please refer to our website at [www.stelpro.com](http://www.stelpro.com).