



SHOP DRAWING

CEILING FAN HEATER SGH SERIES



FEATURES

COLOURS

- standard: red, canary yellow
- luxurious finish: stainless steel (see price list)

FINISH

polyester powdercoat or stainless steel

MANUFACTURING

- 22-gauge smooth steel housing
- quiet helicoidal fan
- thermal protection with automatic reset
- closed and permanently lubricated motor

ELEMENT

nichrome element producing instant heat

CONTROL

wall thermostat (not included) – the use of an electronic thermostat is strongly recommended

INSTALLATION


- ceiling surface mounted with bracket
- from adjacent walls at a minimum of: 12 in. (305 mm)
- from floor at a minimum of 8 ft. (2.4 m) and a maximum of 10 ft. (3 m)



COLOR:

TYPE	QTY	MODEL	WATTS	VOLTS	PH.	ACCESSORIES

TECHNICAL DRAWING

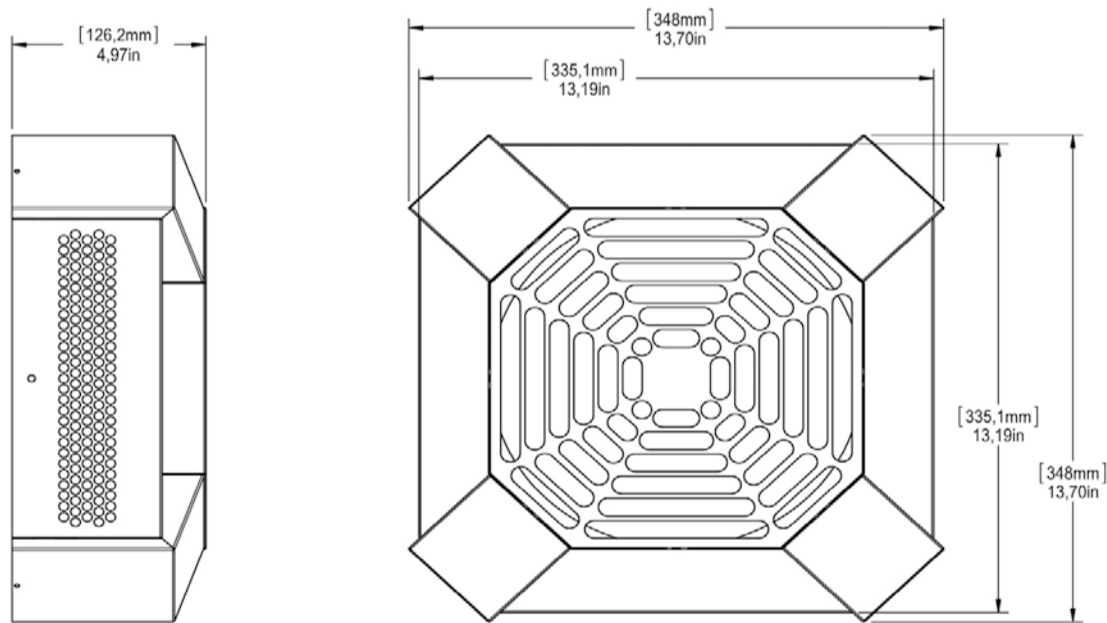

MODEL	DESCRIPTION	DELIVERY TIME

COMMENTS:	PROJECT:	
	CONTRACTOR:	
	DISTRIBUTOR:	
	ENGINEER:	
	ARCHITECT:	
	DATE:	