



# Low Voltage Capsules

## LV Capsule BC10W12V/CAPSULE/TP

Functional light with substantial energy savings Philips Halogen Low Voltage Capsules provide sparkling, white light. These lamps offer an average rated life of 2000 hours making them perfect for undercabinet or task lighting.

### Product data

General Information	
Cap-Base	G4 [ G4]
Operating Position	Universal [ Universal]
Light Technical	
Luminous Flux (Nom)	100 lm
Correlated Color Temperature (Nom)	3000 K
Luminous Efficacy (rated) (Nom)	10 lm/W
Color Rendering Index (Nom)	100
Operating and Electrical	
Power (Rated) (Nom)	10 W
Lamp Current (Nom)	0.83 A
Starting Time (Nom)	0.0 s
Voltage (Nom)	12 V
Controls and Dimming	
Dimmable	Yes


Mechanical and Housing	
Bulb Finish	CL [ Clear (CL)]
Cap-Base Information	na [ -]
Luminaire Design Requirements	
Bulb Temperature (Max)	220 °C
Pinch Temperature (Max)	350 °C
Product Data	
Order product name	LV Capsule CAPSL 10W G4 12V CL 1BL/12
EAN/UPC - Product	046677127435
Order code	127431
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	12
Material Nr. (12NC)	924062117184
Net Weight (Piece)	0.001 kg

### Warnings and Safety

- This lamp is pressurized and could shatter, so to avoid any injury and to avoid exposure to ultraviolet radiation, use only in fixtures that provide a protective shield of tempered glass.

## Low Voltage Capsules

### Dimensional drawing

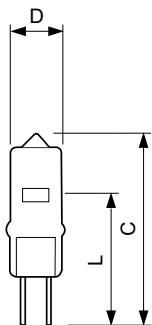

Product	D (max)	L	C (max)
LV Capsule CAPSL 10W G4 12V CL 1BL/12	10 mm	22.2 mm	33 mm

CAP Fighter 10W G4 12V CL

