



A-Shape LED

8.5A19/LED/827 ND 120V


Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.

Product data

General Information		Power Factor (Nom)		0.5	
Cap-Base	E26 [Single Contact Medium Screw]	Voltage (Nom)		120 V	
Nominal Lifetime (Nom)	10950 h	Temperature			
Switching Cycle	50000X				
Technical Type	8.5-60W	T-Case Maximum (Nom)		100 °C	
Controls and Dimming					
Color Code		827 [CCT of 2700K]	Dimmable		No
Mechanical and Housing					
Luminous Flux (Nom)		800 lm	Bulb Finish		FR [Frosted (FR)]
Luminous Flux (Rated) (Nom)		800 lm	Approval and Application		
Color Designation		Warm White (WW)			
Correlated Color Temperature (Nom)		2700 K	Suitable For Accent Lighting		No
Luminous Efficacy (rated) (Nom)		94.00 lm/W	Energy Consumption kWh/1000 h		8.5 kWh
Color Consistency		ANSI	Product Data		
Color Rendering Index (Nom)		80			
LLMF At End Of Nominal Lifetime (Nom)		70 %	Order product name		A19 8.5W 2700K E26
Operating and Electrical					
Input Frequency		60 Hz	EAN/UPC - Product		046677455507
Power (Rated) (Nom)		8.5 W	Order code		455501
Lamp Current (Nom)		125 mA	Numerator - Quantity Per Pack		1
Wattage Equivalent		60 W	Numerator - Packs per outer box		4
Starting Time (Nom)		0.5 s	Material Nr. (12NC)		929001135003
Warm Up Time to 60% Light (Nom)		0.5 s	Net Weight (Piece)		0.052 kg

A-Shape LED

Dimensional drawing

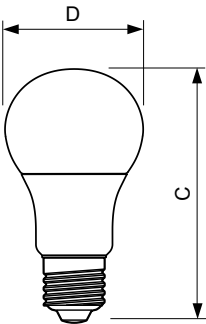

Bulb A19 120V 8.5W-60W 150D 2700K E26 ND

Product	D	C
A19 8.5W 2700K E26	61 mm	107 mm

Photometric data

