



# CorePro LED PL 4pin 2pin

## 10.5PL-C/T LED/26V-4000 IF 4P 1PK 10/1

Philips LED T8 InstantFit Lamps are an ideal energy saving choice for existing linear fluorescent fixtures.

### Product data

General Information	
Cap-Base	G24Q/GX24Q [ G24q/GX24q]
Main Application	Industrial
Nominal Lifetime (Nom)	50000 h
Switching Cycle	50000X
B50L70	50000 h
Light Technical	
Color Code	841 [ CCT of 4100K (841)]
Luminous Flux (Nom)	1300 lm
Luminous Flux (Rated) (Nom)	1300 lm
Correlated Color Temperature (Nom)	4000 K
Color Consistency	<6
Color Rendering Index (Nom)	82
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	20000-100000 Hz
Power (Rated) (Nom)	10.5 W
Lamp Current (Max)	550 mA
Lamp Current (Min)	150 mA
Starting Time (Nom)	0.5 s

Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.9
Voltage (Nom)	120 V
Temperature	
T-Ambient (Max)	45 °C
T-Ambient (Min)	-20 °C
T-Storage (Max)	65 °C
T-Storage (Min)	-40 °C
T-Case Maximum (Nom)	60 °C
Controls and Dimming	
Dimmable	No
Mechanical and Housing	
Product Length	100 mm
Approval and Application	
Energy Saving Product	Yes
Approval Marks	UL certificate RoHS compliance KEMA Keur certificate DLC compliance

# CorePro LED PL 4pin 2pin


DesignLights Consortium Qualified Product List DesignLights Consortium Qualified Product List

## Product Data

Order product name	10.5PL-C/T LED/26V-4000 IF 4P 10/1
EAN/UPC - Product	046677458430
Order code	458430

Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929001388704
Net Weight (Piece)	0.091 kg



## Dimensional drawing

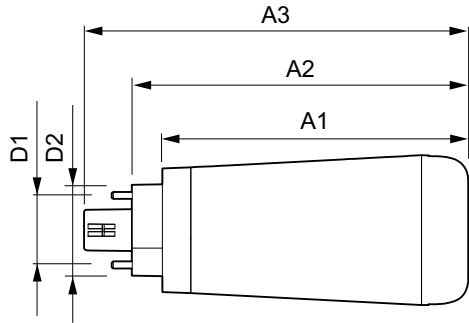

PLED PLC 10.5-26W 1200lm 4000K GX24q


Product	D1	D2	A1	A2	A3
10.5PL-C/T LED/26V-4000 IF 4P	24.3 mm	29 mm	99.9 mm	109.9 mm	125.5 mm
10/1					

## Photometric data

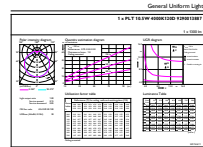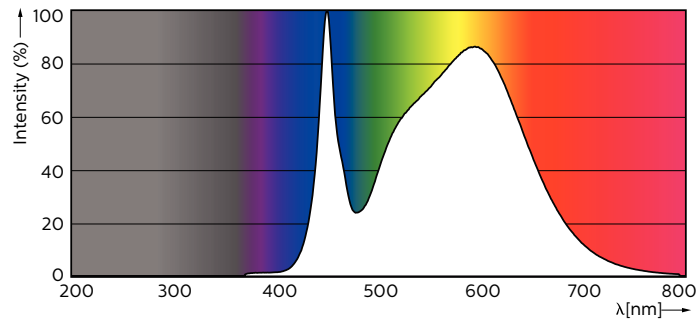

LEDtube PLC 100mm 11W G24Q GX24Q 840 1300lm



LEDtube PLC 100mm 11W G24Q GX24Q 840 1300lm

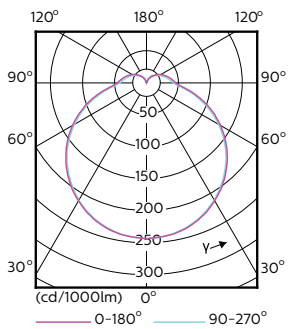

LEDtube PLC 100mm 11W G24Q GX24Q 827 1200lm



# CorePro LED PL 4pin 2pin

## Lifetime

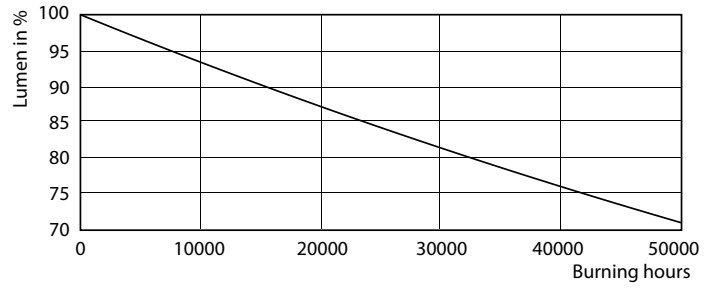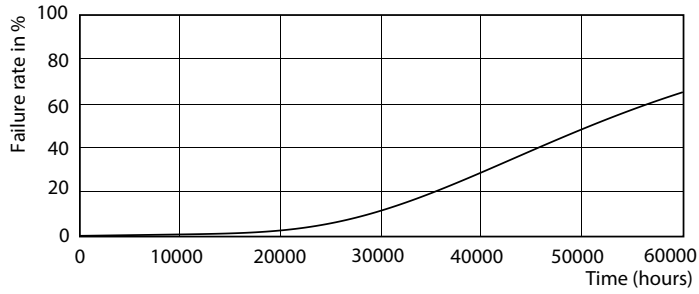


LEDtube PLC 100mm 9W G24Q GX24Q 827 850lm

LEDtube PLC 100mm 9W G24Q GX24Q 827 850lm

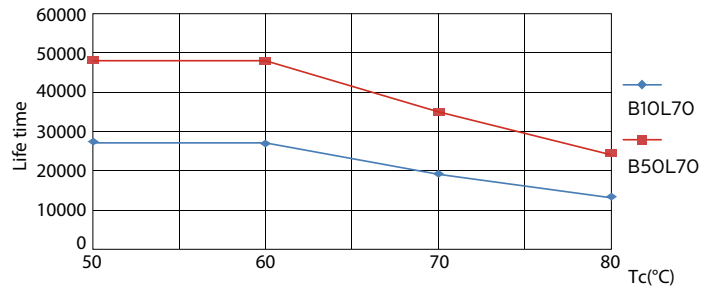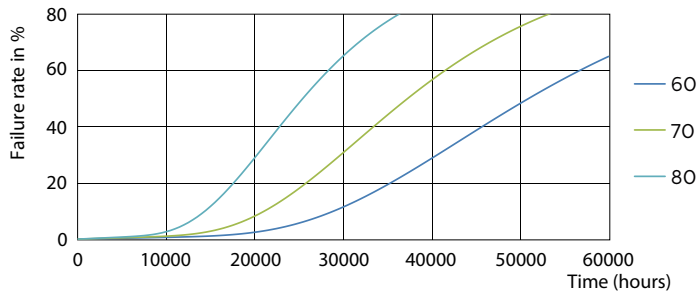

LEDtube PLC 100mm 9W G24Q GX24Q 827 850lm

LEDtube PLC 100mm 9W G24Q GX24Q 827 850lm

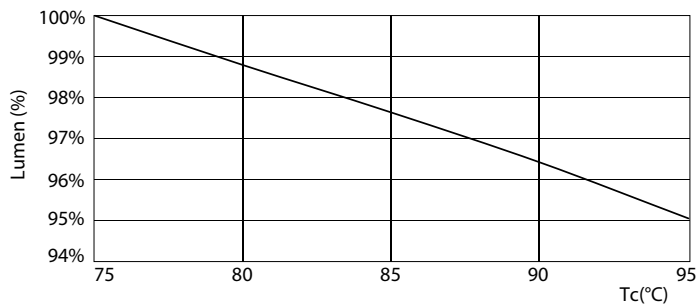

LEDtube PLC 100mm 11W G24Q GX24Q 827 1200lm

## CorePro LED PL 4pin 2pin

