


## Type II® winged

The Marrette Type II winged wire connector is design engineered for additional twisting power to meet the high quality expectations of the electrical professional.

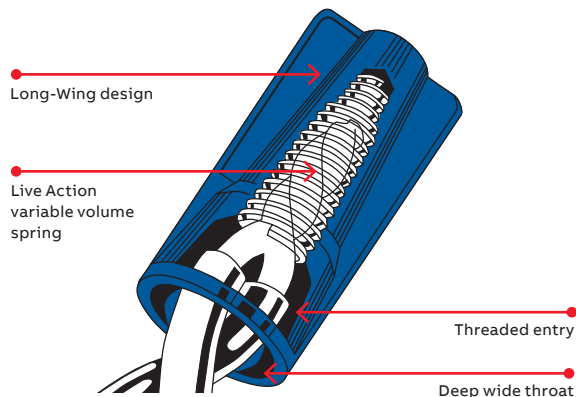

### External cap

- Made of tough, durable polypropylene and 105 °C (221 °F) rated to withstand high installation pressures.
- Long-Wing™ design for smooth hand application. The long, offset wings with raised edges offer a full-length, “finger-friendly” gripping surface. Torque can be selectively applied exactly where you want it:
  - Top – for tight finger locations
  - Bottom – for large wire bundles
- Ribbed body surface gives additional grip, even when hands are greasy or damp.
- Deep, wide throat ensures full insulation coverage.
- Threaded entry helps guide large wire bundles into the spring chamber.
- Colour-coded for quick and easy size selection.

### Inner spring

- Live Action variable volume spring expands to accommodate a wide range of wire combinations.
- Square wire construction gives a positive conductor bite to solid or stranded wires.
- Unique copper-coated spring helps resist corrosion.
- Approved for circuits up to 600 V, and lighting fixtures and signs up to 1000 V.
- For copper conductor only.
- Convenient packaging – sized right and job-site ready.

## Type II® winged

### Ordering information

Model	Colour	AWG wire range							
		22	18	16	14	12	10	8	6
739	Blue								Min. 3 #12, Max. 2 #6

#### Drivers

TOOL-WING	Plastic driver to install model 739 (included in 739KP package)
-----------	---

Note: Refer to page 32 for related wire combination reference guide.

#### Packaging options

Cat. no.	Packaging format	Quantity per package	Std. pkg. (min./mult.)
<b>739</b>			
739B	Window box (retail market only*)	15/Box	10 boxes
739C	Card (retail market only*)	3/Card	20 cards
739P	Propak	50	500 units
739KP	Resealable bag	100	2,500 units
739Q	Flip-pak	250	250 units

\* Retail: Order 1 each for one (1) card/box/flip-pak.