

Luminaire disconnect

The Marrette luminaire disconnect protects electricians servicing fluorescent lights over 150 V from electrical shock.



Suited for

- Fluorescent lighting fixtures and ballasts (OEMs)
- Electricians servicing fluorescent light fixtures
- Maintenance personnel requiring an electrical disconnect

Specifications

Housing: Polycarbonate

Contacts: Tin-plated brass


Integral leads: Insulated #18 AWG solid copper

Max. temp. rating: 105 °C (221 °F)

Flammability: UL94-V2 (V0 available on request)

Electrical rating: 4 A, 600 V

Standards: CSA certified, UL listed, NEC 410.73(G) 2005 edition compliant

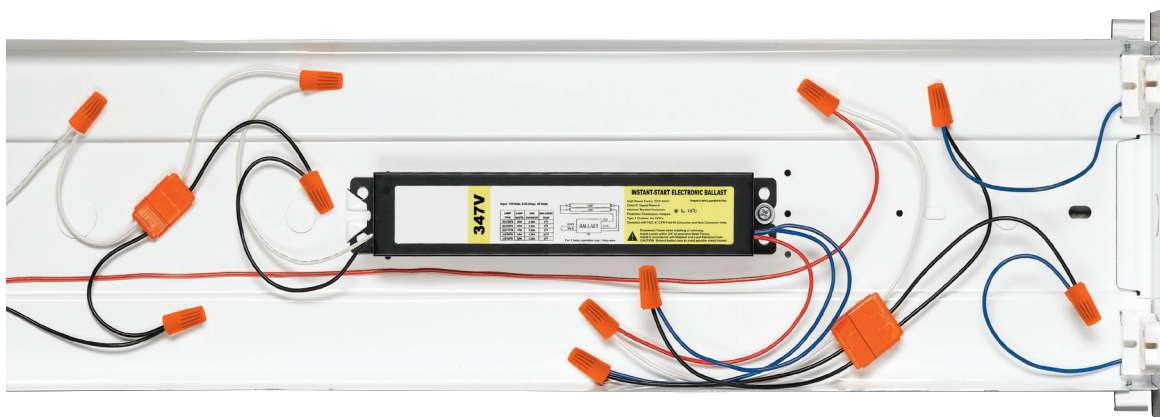

Luminaire disconnect

Ordering information

Model	Description
LD2C-D	2-Pole luminaire disconnect (wire connectors not included)
LD3C-D	3-Pole luminaire disconnect (wire connectors not included)
LD2-C	2-Pole luminaire disconnect (2 x 4 wire connectors 333 /inner bag)
LD3-C	3-Pole luminaire disconnect (6 of each wire connectors 331 + 333) /inner bag)



Cat. no.	Packaging format		Std. pkg. (min./mult.)
Bulk			
LD2C-D	Box	Sold without wire connectors	Inner: 50 per inner bag
LD3C-D		Sold in multiple of 500	Outer: 250 per outer box Master: 500 in master box
Kits			
LD2-C	Bag	Sold with wire connectors	Inner: 2 per inner bag
LD3-C		Sold in multiple of 20	Outer: 20 per outer bag Master: 200 in master box