



Iberville® FS metallic boxes

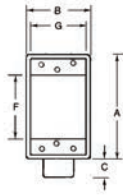

CIFS-1G



CIFS-2G

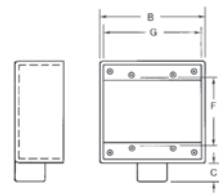


CIFS-3G



Cat. No.	Hub Size	No. of Gangs	No. of Lugs	A (in.)	B (in.)	C (in.)	D (in.)	E (in.)	F (in.)	G (in.)	H (in.)	Cu (in.)
FS Boxes - 1-7/8 in. Deep (Cast Aluminum)												
CIFS-1G-1/2	1 x 1/2	1	3	4-5/16	2-13/16	13/16	1-7/8	1-1/4	2-7/8	2-5/16	1-9/16	14.0
CIFS-1G-3/4	1 x 3/4	1	3	4-5/16	2-13/16	13/16	1-7/8	1-1/2	2-7/8	2-5/16	1-9/16	14.0
CIFS-1G-1	1 x 1	1	3	4-5/16	2-13/16	13/16	1-7/8	1-3/4	2-7/8	2-5/16	1-9/16	14.0
CIFS-2G-1/2	1 x 1/2	2	3	4-3/8	4-11/16	7/8	1-7/8	1-1/4	2-7/8	4-1/4	1-5/8	26.0
CIFS-2G-3/4	1 x 3/4	2	3	4-3/8	4-11/16	7/8	1-7/8	1-9/16	2-7/8	4-1/4	1-5/8	26.0
CIFS-2G-1	1 x 1	2	3	4-3/8	4-11/16	7/8	1-7/8	1-3/4	2-7/8	4-1/4	1-5/8	26.0
CIFS-3G-1/2	1 x 1/2	3	3	4-3/8	6-1/2	7/8	1-7/8	1-1/4	2-7/8	6-1/16	1-5/8	41.0
CIFS-3G-3/4	1 x 3/4	3	3	4-3/8	6-1/2	7/8	1-7/8	1-9/16	2-7/8	6-1/16	1-5/8	41.0



 CIFS-1G-1/2-HV / CIFS-1G-3/4-HV




Cat. No.	Hub Size (in.)	No. of Gangs	No. of Lugs	A (in.)	B (in.)	C (in.)	D (in.)	E (in.)	F (in.)	G (in.)	H (in.)	J (in.)	Cu (in.)
347 Volt FS Box Kits - 1-7/8 in. Deep (Cast Aluminum)													
CIFS-1G-1/2-HV*	1 x 1/2	1	3	4-5/8	2-13/16	13/16	1-7/8	1-1/4	2-7/8	2-5/16	1-9/16	-	14.0
CIFS-1G-3/4-HV*	1 x 3/4	1	3	4-5/8	2-13/16	13/16	1-7/8	1-1/2	2-7/8	2-5/16	1-9/16	-	14.0

* For dry locations only
Includes stamped aluminum "CIFS-9HV" 347 V covers (not raintight)


Iberville® FS metallic boxes



 C1FSC-1G




C1FSC-3G-3/4

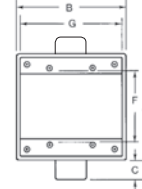

Cat. No.	Hub Size	No. of Gangs	No. of Lugs	A (in.)	B (in.)	C (in.)	D (in.)	E (in.)	F (in.)	G (in.)	H (in.)	Cu (in.)
FS Boxes - 1-7/8 in. Deep (Cast Aluminum)												
C1FSC-1G-1/2	2 x 1/2	1	4	4-5/16	2-13/16	27/32	1-7/8	1-1/4	2-7/8	2-5/16	1-9/16	14.0
C1FSC-1G-3/4	2 x 3/4	1	4	4-5/16	2-13/16	27/32	1-7/8	1-1/2	2-7/8	2-5/16	1-9/16	14.0
C1FSC-1G-1	2 x 1	1	4	4-5/16	2-13/16	27/32	1-7/8	1-3/4	2-7/8	2-5/16	1-9/16	14.0
C1FSC-2G-1/2	2 x 1/2	2	4	4-3/8	4-11/16	31/32	1-7/8	1-1/4	2-7/8	4-1/4	1-5/8	26.0
C1FSC-2G-3/4	2 x 3/4	2	4	4-3/8	4-11/16	31/32	1-7/8	1-9/16	2-7/8	4-1/4	1-5/8	26.0
C1FSC-2G-1	2 x 1	2	4	4-3/8	4-11/16	31/32	1-7/8	1-3/4	2-7/8	4-1/4	1-5/8	26.0
C1FSC-3G-3/4	2 x 3/4	3	4	4-3/8	6-1/2	29/32	1-7/8	1-9/16	2-7/8	6-1/8	1-5/8	41.0



 C1FSCC-1G



Cat. No.	Hub Size (in.)	No. of Gangs	No. of Lugs	A (in.)	B (in.)	C (in.)	D (in.)	E (in.)	F (in.)	G (in.)	H (in.)	J (in.)	Cu (in.)
FSCC Boxes - 1-7/8 in. Deep (Cast Aluminum)													
C1FSCC-1G-1/2	3 x 1/2	1	3	4-5/16	2-13/16	27/32	1-7/8	1-1/4	2-7/8	2-5/16	1-9/16	1-9/16	14.0
C1FSCC-1G-3/4	3 x 3/4	1	3	4-5/16	2-13/16	27/32	1-7/8	1-1/2	2-7/8	2-5/16	1-9/16	1-3/4	14.0