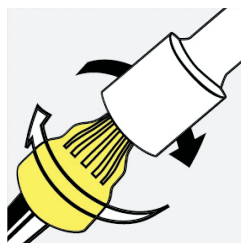
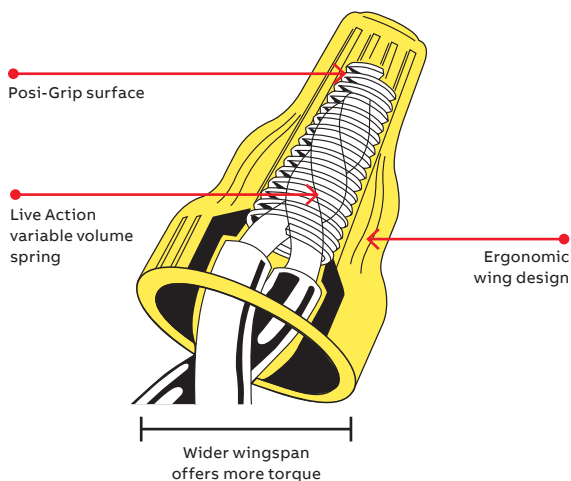

833®

The Marrette 833 is an outstanding wire connector with an ergonomic wing design that can take a wide range of wire combinations from #22 to #8 AWG.



Can also be used with
½ in. or 13 mm nut driver.

External cap

- Ergonomic wing design gives you a comfortable grip and more torque than the competition. The ergonomic shape reduces finger fatigue from repetitive installations.
- The ergonomic wing shape allows excellent torque grip for your fingers as well as the option to use a standard ½ in. or 13 mm hex driver to help twist the wire connector.
- Made of tough durable polypropylene and 105 °C (221 °F) rated to withstand high installation pressures.
- Deep, wide throat ensures full insulation coverage.

Exclusive Live Action variable volume spring expands to accommodate even more wires with less twisting effort compared to other wide range wire connectors.

Inner spring

- Range: #22 to #8 AWG with no pre-twisting.
- The square wire spring construction and funnel design give a positive pressure conductor grip for solid or stranded wires.
- Approved for circuits up to 600 V and lighting fixtures and signs up to 1,000 V.
- For copper conductor only.
- Convenient packaging – sized right and job-site ready.

833®

Ordering information

| Model | Colour | AWG wire range | | | | | | | |
|-------|--------|--------------------------------|----|----|----|----|----|----|---|
| | | 22 | 20 | 18 | 16 | 14 | 12 | 10 | 8 |
| 833 | Yellow | Min. 2 #22 + 1 #20, Max. 3 #10 | | | | | | | |

Drivers

TOOL-WING Driver for winged Marrette connectors (included in the packaging of 833M, 833BK, and 833BAR)

Note: Refer to pages 33-35 for related wire combination reference guide.

Packaging options



| Cat. no. | Packaging format | Quantity per package | Std. pkg. (min./mult.) |
|------------|------------------|----------------------|------------------------|
| 833 | | | |
| 833P | Propak | 100 | 1,000 units |
| 833KP | Resealable bag | 500 | 5,000 units |
| 833D | Flip-pak | 500 | 500 units |
| 833M | Flip-pak | 1,000 | 1,000 units |
| 833BK | Flip-pak | 10,000 | 10,000 units |
| 833BAR | Barrel | 25,000 | 25,000 units |



Packaging options

| Cat. no. | Packaging format | Quantity per package | Std. pkg. (min./mult.) |
|-------------|------------------|----------------------|------------------------|
| 833 | | | |
| 833-JAR200 | Plastic jar | 200 | 200 units |
| 833-JAR400 | Plastic jar | 400 | 400 units |
| 833-JAR1000 | Plastic jar | 1,000 | 1,000 units |