



# Single Ended JC


These lamps provide crisp white light and long reliable life.

## Features

- Crisp white light
- Consistent colour and brightness

## Applications

- Display cases
- Museums
- Restaurants
- Retail stores
- Furniture
- Lounges

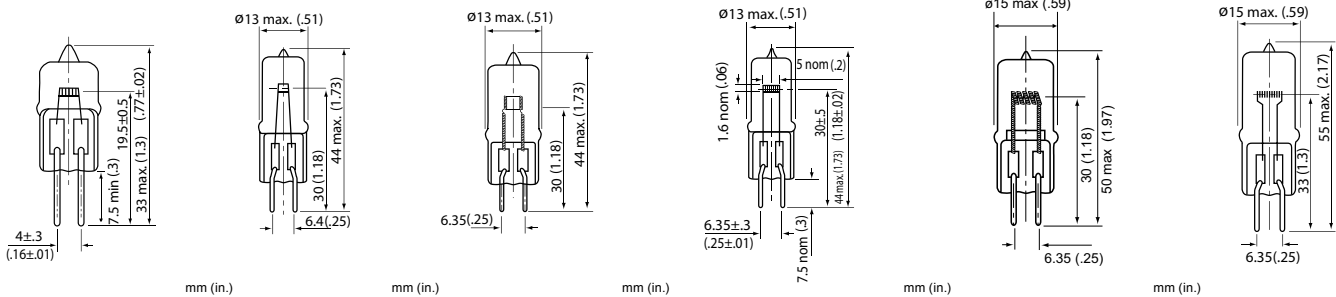

Order code	Description	Watts (W)	Base	Volts (V)	Colour temp. (K)	Initial lumens (lm)	Average life (hrs)	MOL** (in.) (mm)	Case Qty
------------	-------------	-----------	------	-----------	------------------	---------------------	--------------------	------------------	----------

### JC Bi Pin - G4 base

30275	10QT3/G4/6V EYE	10	G4	6	2 850	120	2 000	1.30 33	20
30276	20QT3/G4/6V EYE	20	G4	6	2 850	300	2 000	1.30 33	20
30262	20QT3/G4/12V EYE	20	G4	12	2 850	330	2 000	1.30 33	20

### JC Bi Pin - G1/G6.35 base

30264	30QT3/G6.35/12V EYE	30	G6.35	12	2 900	470	2 000	1.73 44	20
15544	150QT4/G6.35/24V/2000HR EYE	150	G6.35	24	3 000	3 000	2 000	1.97 50	20
15607	100QT3/G6.35/24V EYE	100	G6.35	24	2 900	1 800	2 000	1.73 44	20
15605	JCD150WL/G1 EYE	150	G1	120	3 100	3 300	300	1.97 50	20
15608	JCD250WL/G1 EYE	250	G1	120	3 100	5 750	300	1.97 50	20
15534	JC24V250W20H/G1 EYE	250	G1	24	3 000	4 400	2 000	1.73 44	20

### JC Bi Pin - G2/GY6.35 base

30261	JC12V20W20H/G2 EYE	20	G2	12	2 850	280	2 000	1.73 44	20
30266	35QT3/GY6.35/12V EYE	35	GY6.35	12	2 900	560	2 000	1.73 44	20
30269	50QT3/GY6.35/12V EYE	50	GY6.35	12	3 000	950	2 000	1.73 44	20
30271	75QT3/GY6.35/12V EYE	75	GY6.35	12	3 000	1 420	2 000	1.73 44	20
30274	JC24V300W/G2 EYE	300	G2	24	3 400	9 900	50	2.17 55	20

\*\* Conversions may vary slightly