




LED LPDL™

E-Lume™ LED LPDL™ (Low Profile Downlight) is a simple and economical solution for any downlight application where an even light is needed. Being less than 1" thick, this thin recessed downlight can be installed in all types of ceilings.




03

Order code	Description	Watts (W)	Volts (VAC)	Colour temp. (K)	Lumen output (lm)	CRI	Life L70 (hrs)	Beam angle (°)	Finish	Traditional equivalent (W)	Case qty (master)
4" Round											
66206	LPDL4/RND/11W/30K/WH/ELUME	11	120	3 000	750	≥80	36 000	100	White	60	32
66207	LPDL4/RND/11W/30K/BN/ELUME	11	120	3 000	700	≥80	36 000	100	Brushed nickel	60	32
66208	LPDL4/RND/11W/40K/WH/ELUME	11	120	4 000	750	≥80	36 000	100	White	60	32
66209	LPDL4/RND/11W/40K/BN/ELUME	11	120	4 000	700	≥80	36 000	100	Brushed nickel	60	32
6" Round											
66210	LPDL6/RND/14W/30K/WH/ELUME	14	120	3 000	1 000	≥80	36 000	100	White	75	24
66211	LPDL6/RND/14W/40K/WH/ELUME	14	120	4 000	1 000	≥80	36 000	100	White	75	24

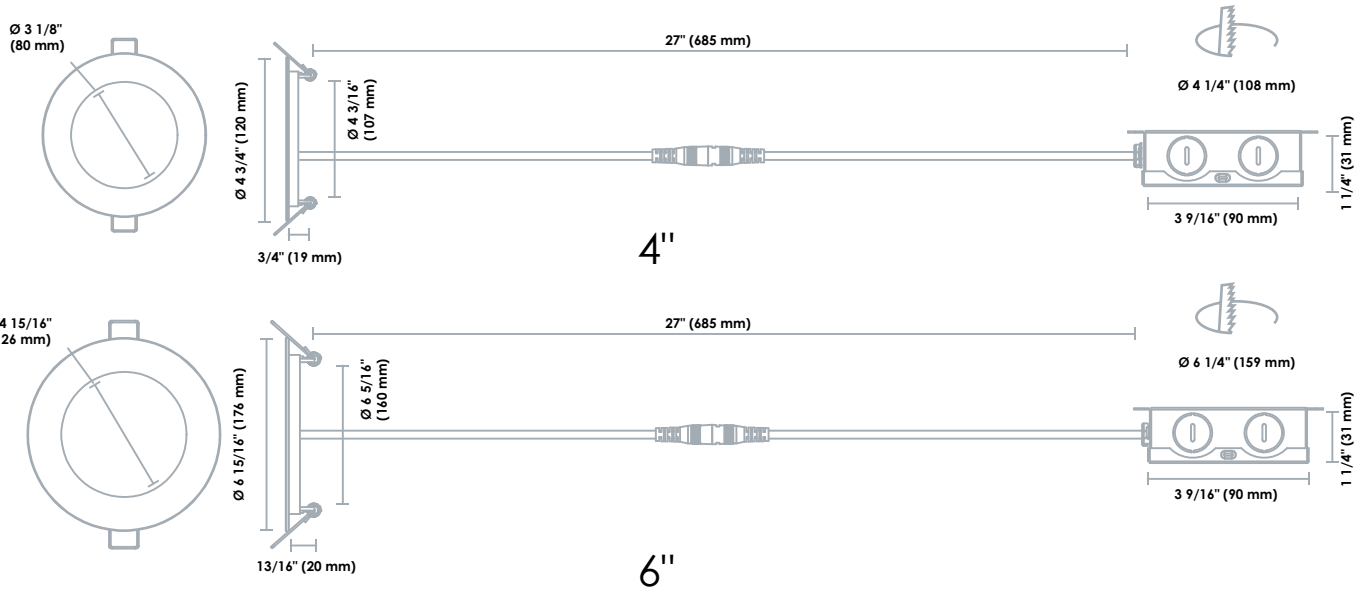

Accessories

Order Code	Description	Opening diameter (in.)	Type	Case qty (master)
66051	ACC/MPLATE/4.25IN/SQR/STD	4 1/4	Square mounting plate	100
66058	ACC/MPLATE/4.25IN/ADJ/STD	4 1/4	Adjustable mounting plate	50
66821	ACC/MPLATE/4.25IN/HANG.BARS/STD	4 1/4	Mounting plate with hanger bars	25
66143	ACC/4/VAPOR BARRIER/STD	4 1/4	Vapor barrier extender	50
66822	ACC/MPLATE/6.25IN/HANG.BARS/STD	6 1/4	Mounting plate with hanger bars	25
64263	ACC/MPLATE/6.25IN/SQR/STD	6 1/4	Square mounting plate	96
64921	ACC/MPLATE/6.25IN/ADJ/STD	6 1/4	Adjustable mounting plate	24
66144	ACC/6/VAPOR BARRIER/STD	6 7/32	Vapor barrier extender	50
64264	LPDL/ACC/6FT/EXTCABLE/STD	-	6' extension cord	96

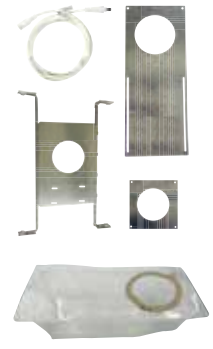

Lumen values are derived from photometric testing. For a complete list of compatible dimmers and ENERGY STAR qualified products, please visit www.standardpro.com

