



SNAP²IT[®] Duplex Connectors

Zinc die-cast.
For AC • MCI-A • HCF steel and aluminum cable • Flexible metal conduit steel and aluminum (regular and reduced wall) • MCI cable • AC90.

CATALOG NUMBER	UPC/DCI/NAE MFG #018997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C	DIM D	CABLE RANGE
3838ST*	10935	3/8	1/2	25	100	1.912	1.738	.970	.620 (2)	.405 - .612
3838AST*	36230	3/8	1/2	25	100	1.772	1.605	.840	.620 (2)	.405 - .612
4040AST†*	40351	3/8	1/2	25	100	1.772	1.605	.840	.620 (2)	.485 - .612

*Provided with insulated throat.


†Provided with insulated throat and red tinted inside clips.

See comparison on page E-1.

SNAP-TITE[®] and SNAP²IT[®] products have been tested and listed by UL in accordance with UL's ground fault requirements. For additional information see page 6.

See page E-25 for MCI-A cable ranges.

Concrete tight when taped.

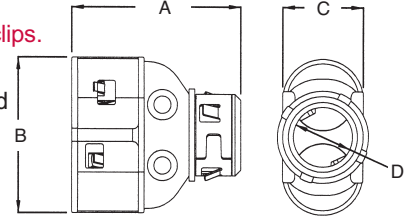


3838AST



4040AST



No Tools Required...Fully Assembled!
Snap cables into connector and snap assembly into box or fixture.

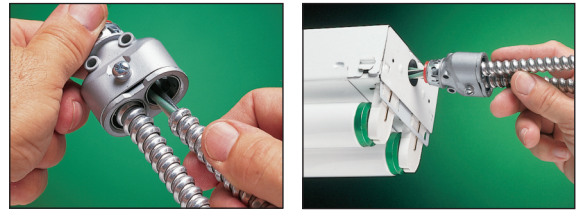

FOR EASIER MCI/AC INSTALLATIONS...
See 383810AST & 404010AST (Above)