

## Weatherproof FS Boxes



One-piece construction electrical box provides a clean, weatherproof, UL Listed installation. Deep design for GFCIs. Paintable, UV rated plastic for long outdoor life.



### FEATURES AND BENEFITS

- Provides a solid, attractive, UL listed installation
- Accommodates GFCI, switches, and outlets
- For use with all siding types... 1/2", 5/8", Dutch Lap, and flat surfaces

CATALOG NUMBER	UPC/DCI/NAED MFG #018997	SIDING TYPE/STYLE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C
FS8141	17340	1/2" Lap	25	25	5.093	3.312	2.056
FS8151	17341	5/8" Lap	25	25	5.093	3.312	2.056
FS8161	17342	Flat Surfaces	25	25	5.093	3.312	2.056
FS8171	17343	Dutch Lap	25	25	5.093	3.312	2.056

Add suffix "GC" to Catalog # when ordering in Canada to include grounding clip, for example FS8141GC.

**PATENTED.**

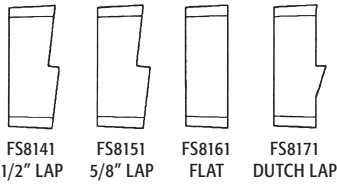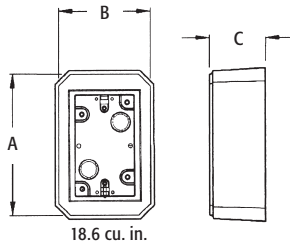

### INSTALLATION INSTRUCTIONS



1 Remove KO from FS Box & insert NM cable connector. Push cable through connector & position box onto siding.



2 Mount box to siding and install your choice of either a GFCI, switch or duplex receptacle.

Complete installation with one of Arlington's code required extra-duty weatherproof while-in-use 60 Series or 61 Series Low Profile IN-AND-OUT™ covers. See Page K-16 for more information.