

Meter Mounting Bases

One-piece construction.
Paintable. Gangable. UV rated plastic for long outdoor life.




FEATURES AND BENEFITS

- Provides a smooth, flat mounting surface
- Provides a 1" overhang to cover siding
- Gangable to accommodate most meter sizes
- Break off flanges for retrofit work

CATALOG NUMBER	UPC/DCI/NAED MFG #018997	SIDING TYPE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C	DIM D
MM10	42278	All Types	10	10	.750	1.125	10.000	7.000
MM18	42280	All Types	10	10	.750	1.125	17.625	15.875
MM23	42282	All Types	10	10	.750	1.125	23.000	17.625

PATENTED.

 Installs before or after the siding is up and works with any siding type!


Installation Instructions

BEFORE siding is up




Note: For support, meter mounting nails or screws must penetrate through mounting base into substrate.

- Fasten to substrate through 'notched flanges'.
- Siding butts to edge of Meter Base, overlapping the 'notched flanges'.
- Meter Base mounting surface provides a 1" overhang to cover cut ends of siding.


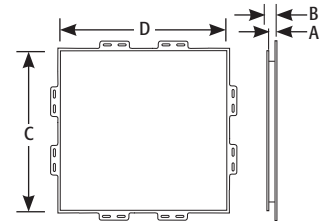


MM10 mounting block also mounts **disconnects, time clocks, cable TV boxes, and more!**

Gangable Meter Base Combinations...

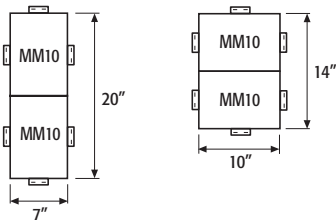

Seal joint channel with Arlington's DSC1 duct sealing compound. See page M-14.

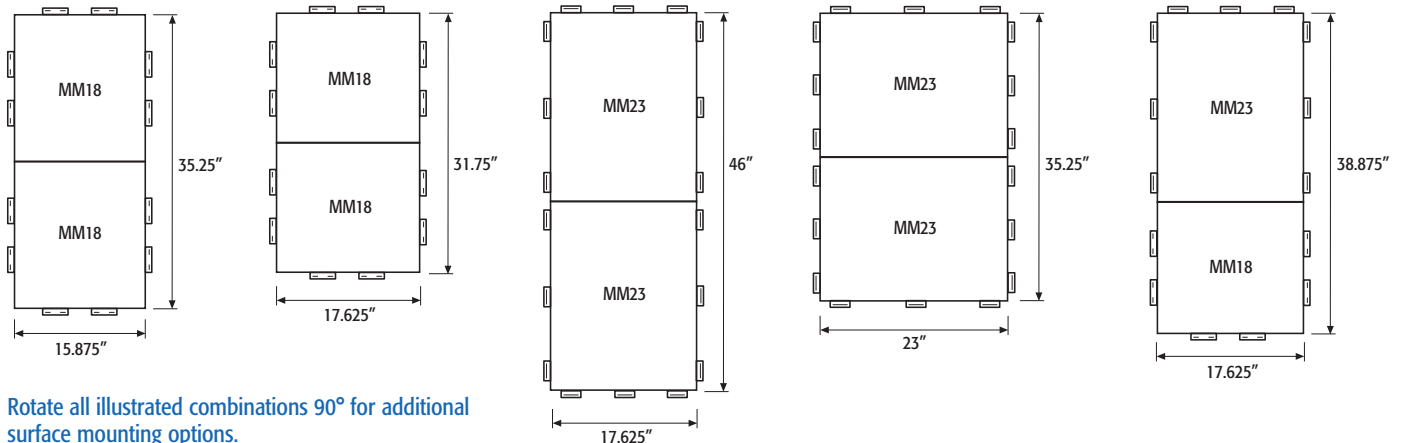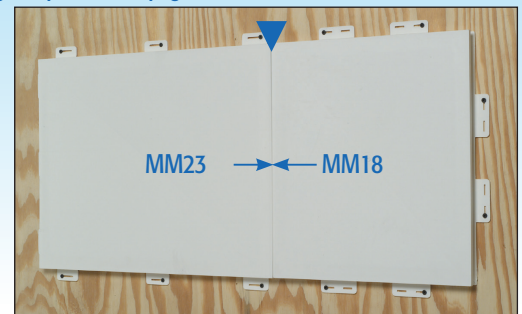

Rotate all illustrated combinations 90° for additional surface mounting options.