

Utility Boxes and Covers



CI2018




CI2018-SB



BC2020



BC2020-R

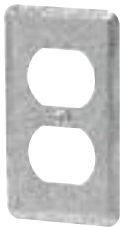

BC20-C-1



BC20-C-3



BC20-C-4



BC20-C-5



Cat. No.	Volume (Cu. in.)	Features		Knockouts		
		Bracket	Raised Ground Screw	1/2 in. ends	1/2 in. bottom	1/2 in. sides
1-1/2 in. Deep — 4 in. x 2-1/4 in.						
CI2018	13.0	-	no	2	2	6
CI2018-SB	13.0	"SB"	no	2	2	3
1-7/8 in. Deep — 4 in. x 2-1/8 in.						
BC2020	14.0	-	yes	2	2	6
BC2020-R	14.0	-	-	2	-	6

Cat. No.	Description
Covers — 20 Series	
BC20-C-1	For duplex receptacle
BC20-C-3	For 1-13/32 in. diameter 15 A single receptacle
BC20-C-4	Blank
BC20-C-5	For toggle switch

Note:
 BC2020-R can be installed on CI2018 / BC2020 Series
 Covers: Device mounting screws included

Utility Boxes and Covers



CI1141



BC1110



CI1110-SB



BC1110-LSKO



BC1110-SSX



BC1110-R



BC1151

BC1151: For toggle switch.



BC1199

BC1199: For duplex receptacle.



BC11-C-1



BC11-C-2



BC11-C-3



BC11-C-4



BC11-C-5



BC11-C-10



CI11-C-10-HV



BC11-C-4-HV



BC11-C-5-HV



Cat. No.	Volume (Cu. in.)	Features		Knockouts		
		Bracket	Raised Ground Screw	1/2 in. ends	1/2 in. bottom	1/2 in. sides
1-1/2 in. Deep – 4 in. x 2-1/4 in.						
CI1141	13.0	mounting ears	no	2	2	6
1-7/8 in. Deep – 4 in. x 2-3/8 in.						
BC1110	16.5	-	yes	2	2	6
CI1110-SB	16.5	"SB"	yes	2	2	3
BC1110-R	16.5	-	-	2	-	6
2-1/8 in. Deep – 4 in. x 2-1/2 in.						
BC1151	18.5	-	no	2	2	-
BC1199	18.5	-	no	2	2	-
1-7/8 in. Deep – 4 in. x 2-3/8 in.						
BC1110-LSKO	16.5	-	yes	2	2	-
BC1110-SSX	16.5	"SSX"	yes	2	2	-

Cat. No.	Description	Cat. No.	Description
Covers – 11 Series			
BC11-C-1	For duplex receptacle	BC11-C-10	Decora/GFCI
BC11-C-2	For 1-19/32 in. diameter 20 A single locking receptacle	CI11-C-10-HV	Decora 347 volt
BC11-C-3	For 1-13/32 in. diameter 15 A single receptacle	BC11-C-4-HV	Blank 347 volt
BC11-C-4	Blank	BC11-C-5-HV	For toggle switch
BC11-C-5	For toggle switch 347 volt	Note: Covers: Device mounting screws included	