

LXOW-25
Ears flush for old work




LXOWC
Adapts to 3/4" wall thickness




LXLE




LXV-25
"CV" bracket recessed 7/8"

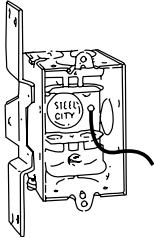

LXVP

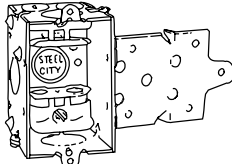

806-S
"S" bracket recessed 5/8"

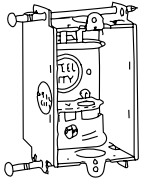

A-256
With nails slanted for easy drive-in




CW-1/2
Ears flush




CW-3/4
Ears flush




CWLE-1/2

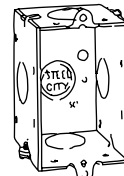


CWLE-3/4

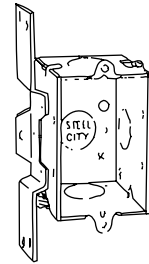


CWV-1/2
"CV" bracket recessed 7/8"

 


CWN-25
Ears flush

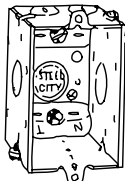


CWNLE

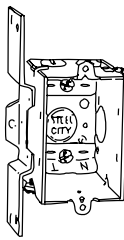

CWNV
"CV" bracket recessed 7/8"

 

CWX
Ears flush

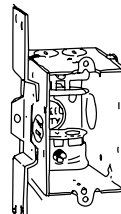

CWXV
"CV" bracket recessed 7/8"

3" x 2" Switch Boxes – Continued

Cat. No.	Clamps	Ears	Brkts.	Knockouts				Std. Ctn.
				Ea. Side Conduit	Ea. End Conduit	Cable	Bottom Conduit	
2 1/2" deep gangable—with armored cable/metal clad clamps—12.5 cubic inch capacity								
LXOW-25	C-3	Yes	—	1-1/2"	—	2	1-1/2"	25
LXOWC-25	C-3	Yes	—	1-1/2"	—	2	1-1/2"	25
LXLE	C-3	—	—	1-1/2"	1-1/2"	2	1-1/2"	25
LXV-25	C-3	—	CV	1-1/2"	1-1/2"	2	1-1/2"	25
LXVP	C-3	—	CV	1-1/2"	1-1/2"	2	1-1/2"	25
806-S	C-3	—	S	1-1/2"	1-1/2"	2	1-1/2"	25
2 1/2" deep non-gangable—with armored cable/metal clad clamps—12.5 cubic inch capacity								
A-256	C-3	—	—	—	1-1/2"	2	1-1/2"	25
2 3/4" deep gangable—with conduit KOs—14.0 cubic inch capacity								
CW-1/2	—	Yes	—	1-1/2"	1-1/2"	—	1-1/2"	50
CW-3/4-25	—	Yes	—	1-3/4"	1-3/4"	—	1-3/4"	25
CWLE-1/2-25	—	—	—	1-1/2"	1-1/2"	—	1-1/2"	25
CWLE-3/4	—	—	—	1-3/4"	1-3/4"	—	1-3/4"	25
CWV-1/2	—	—	CV	1-1/2"	1-1/2"	—	1-1/2"	25
2 3/4" deep gangable—with nonmetallic sheathed cable clamps—14.0 cubic inch capacity								
CWN-25	C-5	Yes	—	1-1/2"	—	2	1-1/2"	25
CWNLE	C-5	—	—	1-1/2"	—	2	1-1/2"	25
CWNV-25	C-5	—	CV	1-1/2"	—	2	1-1/2"	25
2 3/4" deep gangable—with armored cable/metal clad clamps—14.0 cubic inch capacity								
CWX-25	C-3	Yes	—	1-1/2"	—	2	1-1/2"	25
CWXV-25	C-3	—	CV	1-1/2"	—	2	1-1/2"	25