


TYPE Q-F FINGRIP™

NON-INSULATED FEMALE QUICK DISCONNECTS

MATERIAL: TIN-PLATED BRASS

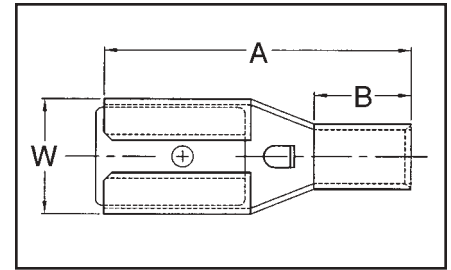

B-35



Features and Benefits

- Butted seam.
- Chamfered barrel opening.
 - ◊ Assures quick and easy wire insertion.
- Dimpled female socket detent.
 - ◊ Ensures firm grip.

FEMALE BARE DISCONNECT TERMINAL

(Mates with Type Q-M male disconnects)


STANDARD CATALOG NO.	STD. PKG. QTY.	WIRE RANGE	NEMA TAB SIZE	DIMENSIONS			BULK CATALOG NO.	BULK QTY.	INSTALLATION TOOL*
				A	B	W			
Q18F18X02D	100	18-22	.187 × .020	0.58	0.17	0.23	Q18F18X02B	1000	MR20, Y10D
Q18F25X03D			.250 × .032	0.62	0.17	0.29	Q18F25X03B		
Q14F11X02D	100	14-16	.110 × .020	0.55	0.17	0.14	Q14F11X02B		
Q14F18X02D			.187 × .020	0.58	0.17	0.20	Q14F18X02B		
Q14F25X03D			.250 × .032	0.62	0.17	0.29	Q14F25X03B		
Q10F25X03D	50	10-12	.250 × .032	0.73	0.27	0.29	Q10F25X03B		

* For UL listed applications consult BURNDY® factory.

TYPE QP-F FINGRIP™

VINYL INSULATED FEMALE QUICK DISCONNECTS

MATERIAL: TIN-PLATED BRASS
600 VOLTS MAX. 105° C MAX.

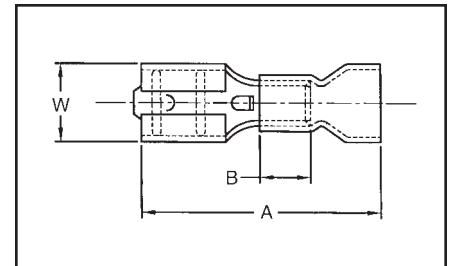

Features and Benefits

- Butted seam.
- Insulated connectors.
 - ◊ Eliminate the need for post installation insulation.
- Funnel entry barrel opening.
 - ◊ Assures quick and easy wire insertion.
- Dimpled female socket detent.
 - ◊ Ensures firm grip.

FEMALE VINYL DISCONNECT TERMINAL

(Mates with Type QP-M male disconnects)

STANDARD CATALOG NO.	STD. PKG. QTY.	WIRE RANGE	NEMA TAB SIZE	DIMENSIONS			BULK CATALOG NO.	BULK PKG. QTY.	INSTALLATION TOOL*	
				A	B	W				
QP18F18X02D	100	18-22	.187 × .020	0.86	0.17	0.22	QP18F18X02B	1000	Y10D	
QP18F25X03D			.250 × .032	0.91	0.17	0.29	QP18F25X03B			
QP14F18X02D	100	14-16	.187 × .020	0.87	0.17	0.23	QP14F18X02B			
QP14F25X03D			.250 × .032	0.92	0.17	0.29	QP14F25X03B			
QP10F25X03D	50	10-12	.250 × .032	1.08	0.27	0.29	QP10F25X03B			500

* For UL listed applications consult BURNDY® factory.

