

Fittings


U-Style Fittings Vertical Bends 90°



Outside Bend



Inside Bend

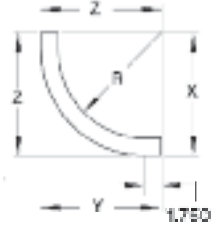

Technical Specifications

Part Numbering System

AUF-7-30-L-VI90-36

| | | | |
|-------------------------------|--------------|--------------|----------------|
| Fitting Material and Siderail | Width | Fitting Type | Nominal Radius |
| Siderail Depth | Bottom Style | Degree | |

Selection Guide

Inside Tray Widths: **6, 9, 12, 18, 24, 30, 36**
 Angle: **90°**
 Radius: **12, 24, 36, 48**
 Bottom Styles: **L-** Ladder, **V-** Ventilated, **S-** Solid
 Siderail Depth: **4 in. – 7 in.**

90° Vertical BEND — U-Style

| Nominal Radius | R | Width | Cat. No. | (+ V0 Siderail Height 4 in. – 7 in.) | | | (+ V1 Siderail Height) | | | | | | | | | | | | |
|----------------|----|-------|------------------------|--------------------------------------|----|----|------------------------|----------|----------|----------|----------|----------|-------|----|----|-------|----|----|--|
| | | | | X | Y | Z | 4 in. | | | 5 in. | | | 6 in. | | | 7 in. | | | |
| | | | | X | Y | Z | X | Y | Z | X | Y | Z | X | Y | Z | X | Y | Z | |
| 12 | 6 | | AUF(+)-06-(*)-(+)90-12 | | | | | | | | | | | | | | | | |
| | 9 | | AUF(+)-09-(*)-(+)90-12 | | | | | | | | | | | | | | | | |
| | 12 | | AUF(+)-12-(*)-(+)90-12 | | | | | | | | | | | | | | | | |
| | 18 | | AUF(+)-18-(*)-(+)90-12 | 12 | 12 | 12 | 17-15/16 | 17-15/16 | 17-15/16 | 18-13/16 | 18-13/16 | 18-13/16 | 20 | 20 | 20 | 21 | 21 | 21 | |
| | 24 | | AUF(+)-24-(*)-(+)90-12 | | | | | | | | | | | | | | | | |
| | 30 | | AUF(+)-30-(*)-(+)90-12 | | | | | | | | | | | | | | | | |
| 24 | 6 | | AUF(+)-06-(*)-(+)90-24 | | | | | | | | | | | | | | | | |
| | 9 | | AUF(+)-09-(*)-(+)90-24 | | | | | | | | | | | | | | | | |
| | 12 | | AUF(+)-12-(*)-(+)90-24 | | | | | | | | | | | | | | | | |
| | 18 | | AUF(+)-18-(*)-(+)90-24 | 24 | 24 | 24 | 29-15/16 | 29-15/16 | 29-15/16 | 30-13/16 | 30-13/16 | 30-13/16 | 32 | 32 | 32 | 33 | 33 | 33 | |
| | 24 | | AUF(+)-24-(*)-(+)90-24 | | | | | | | | | | | | | | | | |
| | 30 | | AUF(+)-30-(*)-(+)90-24 | | | | | | | | | | | | | | | | |
| 36 | 6 | | AUF(+)-06-(*)-(+)90-36 | | | | | | | | | | | | | | | | |
| | 9 | | AUF(+)-09-(*)-(+)90-36 | | | | | | | | | | | | | | | | |
| | 12 | | AUF(+)-12-(*)-(+)90-36 | | | | | | | | | | | | | | | | |
| | 18 | | AUF(+)-18-(*)-(+)90-36 | 36 | 36 | 36 | 41-15/16 | 41-15/16 | 41-15/16 | 42-13/16 | 42-13/16 | 42-13/16 | 44 | 44 | 44 | 33 | 33 | 33 | |
| | 24 | | AUF(+)-24-(*)-(+)90-36 | | | | | | | | | | | | | | | | |
| | 30 | | AUF(+)-30-(*)-(+)90-36 | | | | | | | | | | | | | | | | |
| 48 | 6 | | AUF(+)-06-(*)-(+)90-48 | | | | | | | | | | | | | | | | |
| | 9 | | AUF(+)-09-(*)-(+)90-48 | | | | | | | | | | | | | | | | |
| | 12 | | AUF(+)-12-(*)-(+)90-48 | | | | | | | | | | | | | | | | |
| | 18 | | AUF(+)-18-(*)-(+)90-48 | 48 | 48 | 48 | 53-15/16 | 53-15/16 | 53-15/16 | 54-13/16 | 54-13/16 | 54-13/16 | 56 | 56 | 56 | 57 | 57 | 57 | |
| | 24 | | AUF(+)-24-(*)-(+)90-48 | | | | | | | | | | | | | | | | |
| | 30 | | AUF(+)-30-(*)-(+)90-48 | | | | | | | | | | | | | | | | |

(+) Insert siderail depth. (*) Insert bottom style to complete Cat. No. (+) Insert "V0" for vertical outside or "V1" for vertical inside. Includes 1 pair of splice plates with hardware. T&B aluminum cable tray is composed of two distinct systems H-Style and U-Style. These systems are interchangeable.