


Fittings


U-Style Fittings Vertical Bends 90°



Outside Bend

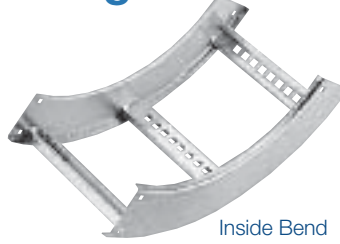

Inside Bend

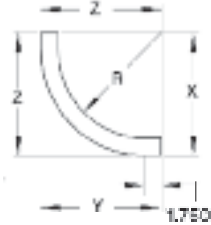

Technical Specifications

Part Numbering System

AUF-7-30-L-VI90-36

Fitting Material and Siderail	Width	Fitting Type	Nominal Radius
Siderail Depth	Bottom Style	Degree	

Selection Guide

Inside Tray Widths: **6, 9, 12, 18, 24, 30, 36**
 Angle: **90°**
 Radius: **12, 24, 36, 48**
 Bottom Styles: **L-** Ladder, **V-** Ventilated, **S-** Solid
 Siderail Depth: **4 in. – 7 in.**

90° Vertical BEND — U-Style

Nominal Radius	R	Width	Cat. No.	(+ V0 Siderail Height 4 in. – 7 in.)			(+ V1 Siderail Height)													
				X	Y	Z	4 in.			5 in.			6 in.			7 in.				
				X	Y	Z	X	Y	Z	X	Y	Z	X	Y	Z	X	Y	Z		
12	6		AUF(+)-06-(*)-(+)90-12																	
	9		AUF(+)-09-(*)-(+)90-12																	
	12		AUF(+)-12-(*)-(+)90-12																	
	18		AUF(+)-18-(*)-(+)90-12	12	12	12	17-15/16	17-15/16	17-15/16	18-13/16	18-13/16	18-13/16	20	20	20	21	21	21		
	24		AUF(+)-24-(*)-(+)90-12																	
	36		AUF(+)-36-(*)-(+)90-12																	
24	6		AUF(+)-06-(*)-(+)90-24																	
	9		AUF(+)-09-(*)-(+)90-24																	
	12		AUF(+)-12-(*)-(+)90-24																	
	18		AUF(+)-18-(*)-(+)90-24	24	24	24	29-15/16	29-15/16	29-15/16	30-13/16	30-13/16	30-13/16	32	32	32	33	33	33		
	24		AUF(+)-24-(*)-(+)90-24																	
	36		AUF(+)-36-(*)-(+)90-24																	
36	6		AUF(+)-06-(*)-(+)90-36																	
	9		AUF(+)-09-(*)-(+)90-36																	
	12		AUF(+)-12-(*)-(+)90-36																	
	18		AUF(+)-18-(*)-(+)90-36	36	36	36	41-15/16	41-15/16	41-15/16	42-13/16	42-13/16	42-13/16	44	44	44	33	33	33		
	24		AUF(+)-24-(*)-(+)90-36																	
	36		AUF(+)-36-(*)-(+)90-36																	
48	6		AUF(+)-06-(*)-(+)90-48																	
	9		AUF(+)-09-(*)-(+)90-48																	
	12		AUF(+)-12-(*)-(+)90-48																	
	18		AUF(+)-18-(*)-(+)90-48	48	48	48	53-15/16	53-15/16	53-15/16	54-13/16	54-13/16	54-13/16	56	56	56	57	57	57		
	24		AUF(+)-24-(*)-(+)90-48																	
	36		AUF(+)-36-(*)-(+)90-48																	

(+) Insert siderail depth. (*) Insert bottom style to complete Cat. No. (+) Insert "V0" for vertical outside or "V1" for vertical inside. Includes 1 pair of splice plates with hardware. T&B aluminum cable tray is composed of two distinct systems H-Style and U-Style. These systems are interchangeable.