


## Galleria

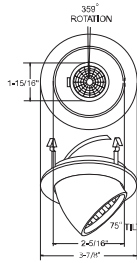

### B1306WH

Fully Adjustable  
(75° Tilt, 359° Rotation)

**DESCRIPTION:**


- Lamp holder adjusts 75° tilt and rotates 359°
- Used to accentuate an artwork or a particular object
- All die-cast construction for functional and aesthetic use
- Relamps from the front

B1306 \_\_\_\_



O. D.	TRIM	HOUSING	MAX. LAMP W.
3-7/8"	WH, BK, SN, CP CH, PB, BZ	BL3IC, BL3, BL3R	50W 12V MR16
		BL3-75	75W 12V MR16
		BL30IC-E, BL3E-S, BL3RE-S	35W 12V MR16

## Galleria

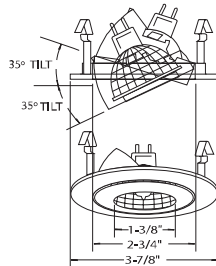

### B1312SN

Fully Adjustable (35° Tilt)

**DESCRIPTION:**


- Offers hidden light technology
- Trim may be regressed or outgressed 35°
- Can take up to 2 optical accessories
- All die-cast construction for functional and aesthetic use
- Unitized optics guarantee proper alignment of lamp

B1312 \_\_\_\_



O. D.	TRIM	HOUSING	MAX. LAMP W.
3-7/8"	WH, BK, SN, CP CH, PB, BZ	BL3IC, BL3, BL3R	50W 12V MR16
		BL3-75	75W 12V MR16
		BL30IC-E, BL3E-S, BL3RE-S	35W 12V MR16
		G3IC, G3, G3R	50W 120V GU10

## Galleria

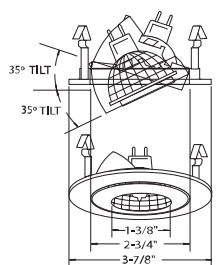

### B1368W-WH

Fully Adjustable w/ Baffle (35° Tilt)

**DESCRIPTION:**

- Offers hidden light technology
- Trim may be regressed or outgressed 35°
- Can take up to 2 optical accessories
- Unitized optics guarantee proper alignment of lamp
- Built w/ deep baffle technology for glare-free illumination

B1368 \_\_\_\_ - \_\_\_\_



O. D.	AVAILABLE COLORS	HOUSING	MAX. LAMP W.
3-7/8"	CP-CP, SN-SN, W-WH, P-WH, P-BK, BZ-BZ	BL3IC, BL3, BL3R	50W 12V MR16
		BL3-75	75W 12V MR16
		BL30IC-E, BL3E-S, BL3RE-S	35W 12V MR16
		G3IC, G3, G3R	50W 120V GU10



**MR16 LENS FILTER**

- BP8MR16-BL BLUE
- BP8MR16-GR GREEN
- BP8MR16-PI PINK
- BP8MR16-PU PURPLE
- BP8MR16-DL DAY LIGHT

- BP8MR16-YE YELLOW
- BP8MR16-AM AMBER
- BP8MR16-OR ORANGE
- BP8MR16-RE RED



- |               |             |
|---------------|-------------|
| <b>CAT. #</b> | <b>TYPE</b> |
| 1. BP8MR16-FR | FROSTED     |
| 2. BP8MR16-SP | SPREAD      |
| 3. BP8MR16-SF | SOFT FOCUS  |
| 4. BP8MR16-HC | HONEY COMB  |

- |                |             |
|----------------|-------------|
| <b>CAT. #</b>  | <b>TYPE</b> |
| 5. BP8MR16-LI  | LINEAR      |
| 6. BP8MR16-SOL | SOLITE      |
| 7. BP8MR16-CL  | CLEAR       |
| 8. BP8MR16-UV  | ULTRAVIOLET |