

B5R

5" Universal Non-IC Remodel Housing

LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30

Catalog Number:

Project Name:

Type:

Note:



DESIGNED FOR 2" X 8" JOIST CONSTRUCTION

DESCRIPTION

Thermally protected, IC rated specification grade remodel recessed housing. For remodeling installations where housing will be in direct contact with insulation. For fast and easy installation in existing plaster or mechanical ceilings from 1/2" to 1-3/8" thick. Four remodel clips are easily retractable for fixture removal if necessary. Junction box is provided with eight 1/2" KOs and four Romex knockouts with a strain relief. Accommodates up to 75W PAR30, R30 lamps, 60W A19 lamps and 65W BR30 lamps.

SPECIFICATION


A. HOUSING - Die-formed, all aluminum construction for maximum heat dissipation and rust protection.

B. SOCKET - Medium base screw shell porcelain socket snaps into trim to allow usage of different lamp types, as well as proper and consistent lamp positioning.

C. INSTALLATION - Four Preinstalled spring clips which secure the housing firmly into ceiling and accommodate ceiling thickness from 1/2" to 1-3/8".

D. JUNCTION BOX - UL and ETL listed for feed through wiring, provided with eight 1/2" KOs and four Romex knockouts with strain relief.

E. THERMAL PROTECTION - Standard thermal protection device guards against improper installation, overlamping and misuse of insulation material.

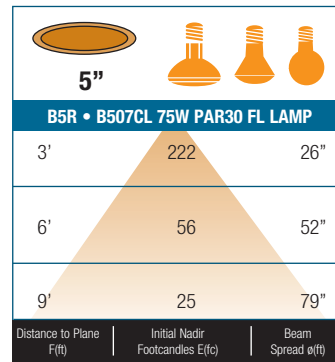

BEAM DIA. MEASURED AT 50% OF NADIR F.C.

FEATURES

- Thermally Protected Non-IC remodel housing.
- Dependable, favorable design and effortless installation.
- Unit slips through 5-1/2" ceiling opening.
- Four Preinstalled spring clips which secure the housing firmly into ceiling to accommodate ceiling thickness from 1/2" to 1-3/8".
- Can be installed from below the ceiling.
- 7" height allows use in 2" x 8" joist construction.
- Wire through junction box.
- Preinstalled socket cap provides electrical contact protection against dust, paint and over spray.


OPTIONS

AIR-SHUT

- Gasket to prevent air flow from heated or air conditioned spaces.
- Meets all national air flow requirements.

UL AND C-UL/ETL AND C-ETL LISTED

- For Damp location
- For Feed-through wiring

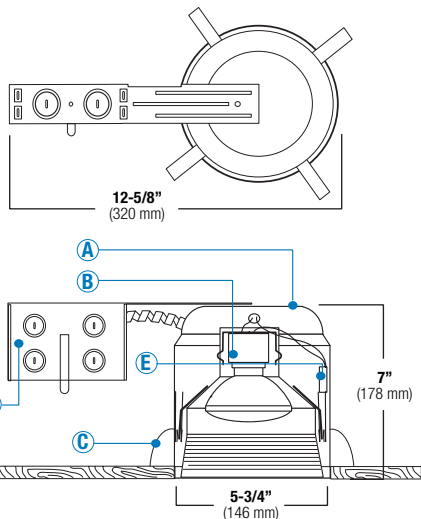

ITEM SELECTOR: (Please check the boxes below for the option desired)

TYPE	AIR-SHUT	OPTION	TRIM TYPE	BAFFLE	REFLECTOR	TRIM/RING	GLASS
B5R	<input type="checkbox"/> AT	<input type="checkbox"/> (W) With quick connects	<input type="checkbox"/> B530 <input type="checkbox"/> B507 <input type="checkbox"/> B563 <input type="checkbox"/> B502 <input type="checkbox"/> B520 <input type="checkbox"/> B573 <input type="checkbox"/> B504 <input type="checkbox"/> B501 <input type="checkbox"/> B505 <input type="checkbox"/> B535 <input type="checkbox"/> B536	<input type="checkbox"/> B541 <input type="checkbox"/> B542 <input type="checkbox"/> B504L <input type="checkbox"/> B501L <input type="checkbox"/> B505L	<input type="checkbox"/> W <input type="checkbox"/> P <input type="checkbox"/> SN <input type="checkbox"/> CP <input type="checkbox"/> BZ	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN <input type="checkbox"/> CP <input type="checkbox"/> CH <input type="checkbox"/> PB <input type="checkbox"/> BZ	<input type="checkbox"/> Green <input type="checkbox"/> Yellow <input type="checkbox"/> Pink <input type="checkbox"/> Brown <input type="checkbox"/> Navy Blue <input type="checkbox"/> Orange <input type="checkbox"/> Blue <input type="checkbox"/> White <input type="checkbox"/> Red

Specifications:

B5R

AIR-SHUT OPTION TRIM TYPE BAFFLE REFLECTOR TRIM/RING GLASS

BAFFLE	REFLECTOR	TRIM/RING
W White	CL Chrome	WH White
P Black	RG Gold	BK Black
SN Satin Nickel	W White	SN Satin Nickel
CP Copper	MB Black	CP Copper
BZ Bronze	BZ Bronze	CH Chrome
	CP Copper	PB Polish Brass
	SN Satin Nickel	BZ Bronze
	SHZ Satin Haze	

Sample of Catalog Number: B5R-AT-W-B530-W-WH

*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.



Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions subject to change without notice.

REV: ELITE LIGHTING-SPEC-06-29-2011

5" Incandescent Trims

(LAMP WATTAGE: 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:


Note:



**B530CP-CP
STEPPED BAFFLE**




AVAILABLE COLOR COMBINATIONS:
CP-CP, SN-SN, W-WH, P-WH, P-BK, BZ-BZ

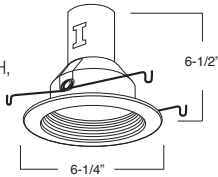


**B507RG-WH
REFLECTOR**




AVAILABLE COLOR COMBINATIONS:
CP-CP, W-WH, RG-WH, MB-WH, CL-WH, MB-BK, RG-PB, CL-CH

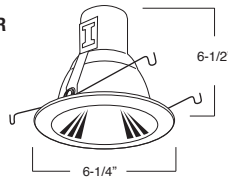

**B563PB
PAR30 GIMBAL TRIM**

 


TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

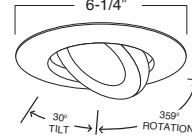

**B502SN
EYEBALL**




TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

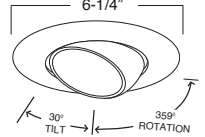

**B520-NAVY BLUE
GLASS TRIM**




GLASS FINISH:
GREEN, YELLOW, PINK, BROWN, NAVY BLUE, ORANGE, WHITE, RED

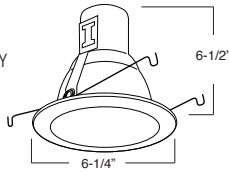

**B573W-WH
PAR30 BAFFLE W/ GIMBAL RING**



AVAILABLE COLOR COMBINATIONS:
CP-CP, SN-SN, W-WH, P-WH, P-BK

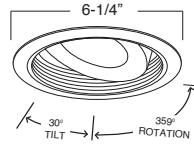


**B504WH
SHOWER TRIM**



FOR WET LOCATION

TRIM/RING FINISH:
WH, BK, SN, CP, CH, BZ

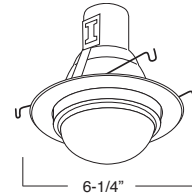


**B501CP
METAL ALBALITE LENS**



FOR WET LOCATION

TRIM/RING FINISH:
WH, BK, SN, CP, CH, BZ

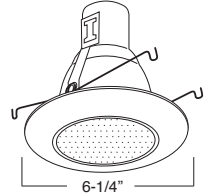


**B505SN
METAL FRESNEL LENS**



FOR WET LOCATION

TRIM/RING FINISH:
WH, BK, SN, CP, CH, BZ

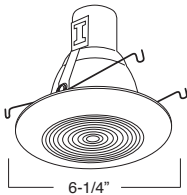


**B535P-WH
BAFFLE WITH ALBALITE LENS**



FOR WET LOCATION

 AVAILABLE COLOR COMBINATIONS:
CP-CP, SN-SN, W-WH, P-WH, P-BK




**B536W-WH
BAFFLE WITH FRESNEL LENS**



FOR WET LOCATION

 AVAILABLE COLOR COMBINATIONS:
CP-CP, SN-SN, W-WH, P-WH, P-BK




**B541RG-WH
REFLECTOR WITH ALBALITE LENS**



FOR WET LOCATION

 AVAILABLE COLOR COMBINATIONS:
CP-CP, W-WH, RG-WH, MB-BK, CL-WH, MB-BK, RG-PB, CL-CH




**B542CL-WH
REFLECTOR WITH FRESNEL LENS**



FOR WET LOCATION

 AVAILABLE COLOR COMBINATIONS:
CP-CP, W-WH, RG-WH, MB-BK, CL-WH, MB-BK, RG-PB, CL-CH




**B504L
PLASTIC SHOWER TRIM**



FOR WET LOCATION

TRIM/RING FINISH:
WHITE PLASTIC

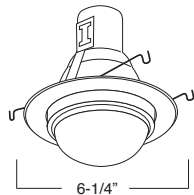


**B501L
PLASTIC ALBALITE LENS**



FOR WET LOCATION

TRIM/RING FINISH:
WHITE PLASTIC

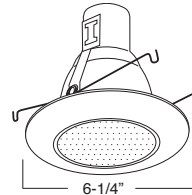

**B505L
PLASTIC FRESNEL LENS**



FOR WET LOCATION

TRIM/RING FINISH:
WHITE PLASTIC

