

Technical Specifications



CI8903 /
CI8904 /




CI8910 /
CI8912



CI8905



CI8920 (2-1/2") /
CI8922 (3")

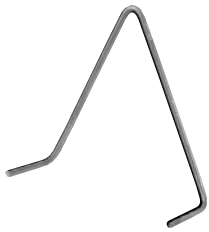

CI8930



CI8932



CI8960



CIDUCT-1 /
CIDUCT-5

Cat. No.	Trade Size	Working Load
"Lion" Chain (Zinc Plated Steel)		
CI8903	#2	115 lb. (52kg)
CI8904	#3	90 lb. (40kg)
"Jack" Chain (Zinc Plated Steel)		
CI8910	#10-T	43 lb. (19kg)
CI8912	#12	29 lb. (13kg)
"S" Hooks (Zinc Plated Steel)		
CI8905	#105	90 lb. (40kg)
"Screw" Hooks (Zinc Plated Steel)		
CI8920	#M-10	90 lb. (40kg)
CI8922	#M-12	115 lb. (52kg)
Fixture Hooks - 90° (Zinc Plated Steel)		
CI8930	—	115 lb. (52kg)
Fixture Hooks - Looped (Zinc Plated Steel)		
CI8932	—	115 lb. (52kg)
Tie Wire (Steel - Gauge No. 16)		
CI8960 (300' Coil)	0.06	125 lb. (56kg)

Cat. No.	Trade Size
Duct Seal Compound (Asbestos Free)	
CIDUCT-1	1lb.
CIDUCT-5	5lb.

SEALS IRREGULAR OPENING FROM AIR, DUST OR WATER. Non-hardening sealant that adheres to metal, masonry, wood or plastic. Meets requirement of clause 12.018 CDN ELECTRICAL CODE Part 1. Safe and easy to use. - NON-CORROSIVE - NON-TOXIC - NO ASBESTOS - NO UNPLEASANT ODOR - WILL NOT STAIN OR HARM HANDS. TEMPERATURE Continuous operating range: -34°C to 88°C (-30°F to 190°F) Minimum Temperature for installation: -12°C (10°F).