




PRODUCT SEARCH

> SUPP
> DIST

[HOME](#)
[WHAT'S NEW](#)
[SERVICE / SUPPORT](#)
[WHERE TO BUY](#)
[INSTRUCTION MANUALS](#)
[CO](#)

TERMINATION

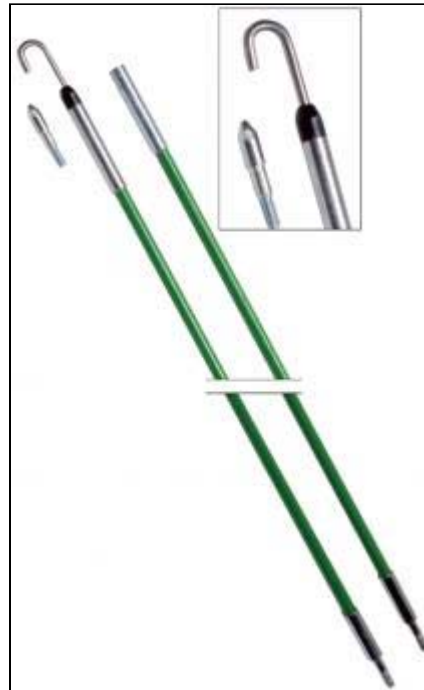[Hand Tools](#)
[Holemaking](#)
[Bending](#)
[Fishing](#)
[Cable Pulling](#)
[Wire & Cable Termination](#)
[Voice Data Video](#)
[Testing & Measurement](#)
[Storage & Material Handling](#)
[Hydraulic Pumps & Miscellaneous](#)


Name:

Fish Stix 12' (3.6 m) kit with bullet nose and 'J' hook threaded tips, packaged in clear plastic tube.

Cat #:

540-12

UPC #:

10504


Spec:

540-12 -- Total Length 12' (3.6 m) - (3) 4' (1.2 m) sections Weight 1.04 lbs. (.5 kg) Material 1/4"

Description:

High visible green color rods can be easily threaded together and seen when working above ceilings, down walls, or under raised floors.

- 1/4" (6.4 mm) diameter fiberglass rods provide added rigidity when multiple sections are connected.
- 200 lbs (0.9 kN) minimum pulling strength for long lasting durability and peace of mind.
- Two different threaded tips available to accommodate various bundles of wire or cable.
-

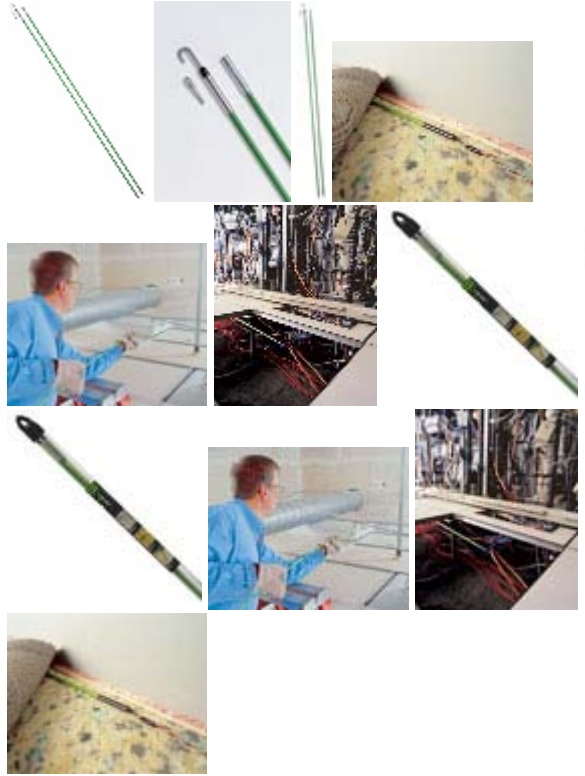

© 2007 Greenlee Textron Inc., a subsidiary of **Textron Inc.** All rights reserved.

[Privacy Policy](#) [Terms of Use](#) [Careers](#)