



T1

DUCT SERIES

Material

Rigid PVC,
self-extinguishing

Color

Light GREY RAL 7030
WHITE

Standard Length

6 Feet 6 3/4 Inches

Standard Unit

Duct complete
with cover

THE MOST COMPREHENSIVE RANGE

NOMINAL 1/2"-2 1/4"-3"-4"



NOMINAL 1/2"-1"



All wiring ducts come complete with cover. Wiring duct covers can be sold separately: see page 8 and IBOCO Corp. Price List.

| Catalog Number | Nominal Size (WxD) | Dimensions in inches (Actual) | | | | Dimensions WxD (in millimeters) | Standard Carton (Qty) | |
|----------------|--------------------|-------------------------------|------|-----|-----|---------------------------------|-----------------------|------|
| | | W | H | E | F | | Length (1) | Feet |
| T1-0506G | 1/2 x 3/8 | .60 | .71 | .20 | .30 | 15 x 18 | 20 | 120 |
| T1-0510G | 1/2 x 1 | .60 | 1.18 | .20 | .30 | 15 x 30 | 20 | 120 |
| T1-0522G | 1/2 x 2 1/4 | .60 | 2.36 | .20 | .30 | 15 x 60 | 16 | 96 |
| T1-1010* | 1 x 1 | 1.00 | 1.18 | .20 | .30 | 25 x 30 | 18 | 108 |
| T1-1015* | 1 x 1 1/2 | 1.00 | 1.57 | .31 | .47 | 25 x 40 | 18 | 108 |
| T1-1022* | 1 x 2 1/4 | 1.00 | 2.36 | .31 | .47 | 25 x 60 | 24 | 144 |
| T1-1030* | 1 x 3 | 1.00 | 3.15 | .31 | .47 | 25 x 80 | 24 | 144 |
| T1-1040* | 1 x 4 | 1.00 | 3.94 | .31 | .47 | 25 x 100 | 8 | 48 |
| T1-1515* | 1 1/2 x 1 1/2 | 1.57 | 1.57 | .31 | .47 | 40 x 40 | 20 | 120 |
| T1-1522* | 1 1/2 x 2 1/4 | 1.57 | 2.36 | .31 | .47 | 40 x 60 | 18 | 108 |
| T1-1530* | 1 1/2 x 3 | 1.57 | 3.15 | .31 | .47 | 40 x 80 | 16 | 96 |
| T1-1540* | 1 1/2 x 4 | 1.57 | 3.94 | .31 | .47 | 40 x 100 | 8 | 48 |
| T1-2215G | 2 1/4 x 1 1/2 | 2.36 | 1.57 | .31 | .47 | 60 x 40 | 12 | 72 |
| T1-2222* | 2 1/4 x 2 1/4 | 2.36 | 2.36 | .31 | .47 | 60 x 60 | 12 | 72 |
| T1-2230* | 2 1/4 x 3 | 2.36 | 3.15 | .31 | .47 | 60 x 80 | 12 | 72 |
| T1-2240* | 2 1/4 x 4 | 2.36 | 3.94 | .31 | .47 | 60 x 100 | 4 | 24 |
| T1-3015G | 3 x 1 1/2 | 3.15 | 1.57 | .31 | .47 | 80 x 40 | 12 | 72 |
| T1-3022* | 3 x 2 1/4 | 3.15 | 2.36 | .31 | .47 | 80 x 60 | 12 | 72 |
| T1-3030* | 3 x 3 | 3.15 | 3.15 | .31 | .47 | 80 x 80 | 12 | 72 |
| T1-3040* | 3 x 4 | 3.15 | 3.94 | .31 | .47 | 80 x 100 | 4 | 24 |
| T1-3050* | 3 x 5 | 2.95 | 4.92 | .31 | .47 | 75 x 125 | 6 | 36 |
| T1-4015G | 4 x 1 1/2 | 3.94 | 1.57 | .31 | .47 | 100 x 40 | 8 | 48 |
| T1-4022G | 4 x 2 1/4 | 3.94 | 2.36 | .31 | .47 | 100 x 60 | 8 | 48 |
| T1-4030* | 4 x 3 | 3.94 | 3.15 | .31 | .47 | 100 x 80 | 8 | 48 |
| T1-4040* | 4 x 4 | 3.94 | 3.94 | .31 | .47 | 100 x 100 | 4 | 24 |
| T1-4050* | 4 x 5 | 3.94 | 4.92 | .31 | .47 | 100 x 125 | 4 | 24 |
| T1-6040* | 6 x 4 | 5.91 | 3.94 | .31 | .47 | 150 x 100 | 4 | 24 |


Example: T1-0510 G = 1/2" x 1" light GREY duct with cover

(1) Each standard length is actually 6'6 3/4" but is counted as 6 feet for packaging and pricing

* Color - add suffix "G" for light GREY "W" for WHITE

ADHESIVE BACKING - add suffix "A" to catalog number - contact sales office for pricing (see page 23)

Available in 1 meter length contact sales office

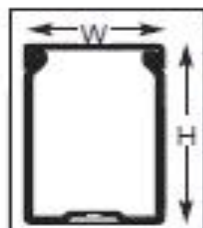

Non-slip cover design of minimum encumbrance and maximum grip.



Restricted slot opening for wire retaining.

Two predetermined breaklines:
- for breaking off and removal of sidewall finger segments only.
- for removal of sidewall finger and base segments.

Burr-free edges.



Recess boss for rapid mounting of components.

For wire fill capacity and base perforation of the wiring duct, see page 18.