

T1-E



DUCT SERIES

Material

Rigid PVC,
self-extinguishing

Color

Light GREY RAL 7030
WHITE

Standard Length

6 Feet 6 3/4 Inches

Standard Unit

Duct complete
with cover

Catalog Number	Nominal Size (WxD)	Dimensions in Inches (Actual)				Dimensions (in millimeters)		Standard Carton (Qty)	
		W	H	E	F	W	H	Length (ft)	Feet
T1E-1015*	1 x 1½	1.00	1.57	.16	.24	25 x 40	18	108	
T1E-1022*	1 x 2¼	1.00	2.36	.16	.24	25 x 60	24	144	
T1E-1030*	1 x 3	1.00	3.15	.16	.24	25 x 80	24	144	
T1E-1040*	1 x 4	1.00	3.94	.16	.24	25 x 100	8	48	
T1E-1515*	1½ x 1½	1.57	1.57	.16	.24	40 x 40	20	120	
T1E-1522*	1½ x 2¼	1.57	2.36	.16	.24	40 x 60	18	108	
T1E-1530*	1½ x 3	1.57	3.15	.16	.24	40 x 80	18	108	
T1E-1540*	1½ x 4	1.57	3.94	.16	.24	40 x 100	8	48	
T1E-2215G	2¼ x 1½	2.36	1.57	.16	.24	60 x 40	12	72	
T1E-2222*	2¼ x 2¼	2.36	2.36	.16	.24	60 x 60	12	72	
T1E-2230*	2¼ x 3	2.36	3.15	.16	.24	60 x 80	12	72	
T1E-2240*	2¼ x 4	2.36	3.94	.16	.24	60 x 100	4	24	
T1E-3015G	3 x 1½	3.15	1.57	.16	.24	80 x 40	12	72	
T1E-3022*	3 x 2¼	3.15	2.36	.16	.24	80 x 60	12	72	
T1E-3030*	3 x 3	3.15	3.15	.16	.24	80 x 80	12	72	
T1E-3040*	3 x 4	3.15	3.94	.16	.24	80 x 100	4	24	
T1E-4015G	4 x 1½	3.94	1.57	.16	.24	100 x 40	8	48	
T1E-4022G	4 x 2¼	3.94	2.36	.16	.24	100 x 60	8	48	
T1E-4030*	4 x 3	3.94	3.15	.16	.24	100 x 80	8	48	
T1E-4040*	4 x 4	3.94	3.94	.16	.24	100 x 100	4	24	


Example: T1E-1015 G - 1"x1½" light GREY duct with cover

Available in 1 meter length
contact sales office


(1) Each standard length is actually 6' 3/4"
but is counted as 6 feet for packaging and pricing

* Color - add suffix "G" for light GREY "W" for WHITE

ADHESIVE BACKING - add suffix "A" to catalog number -
contact sales office for pricing (see page 22)

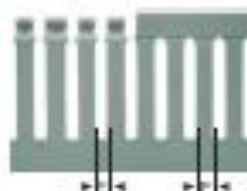

All wiring ducts come
complete with cover.
Wiring duct covers can
be sold separately.
see page 8 and
IBOCD Corp. Price List.

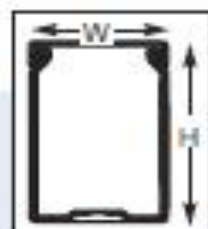

Restricted slot
opening for
wire
retaining.

Two predetermined
breaklines:
- for breaking off and
removal of sidewall
finger segments only.
- for removal of sidewall
finger and base segments.

Burr-free edges.

Recess boss for rapid
mounting
of components.

Non-slip cover
design of minimum
encumbrance and
maximum grip.

For wire fill capacity and base perforation of the wiring duct, see page 18.