


MINIATURES

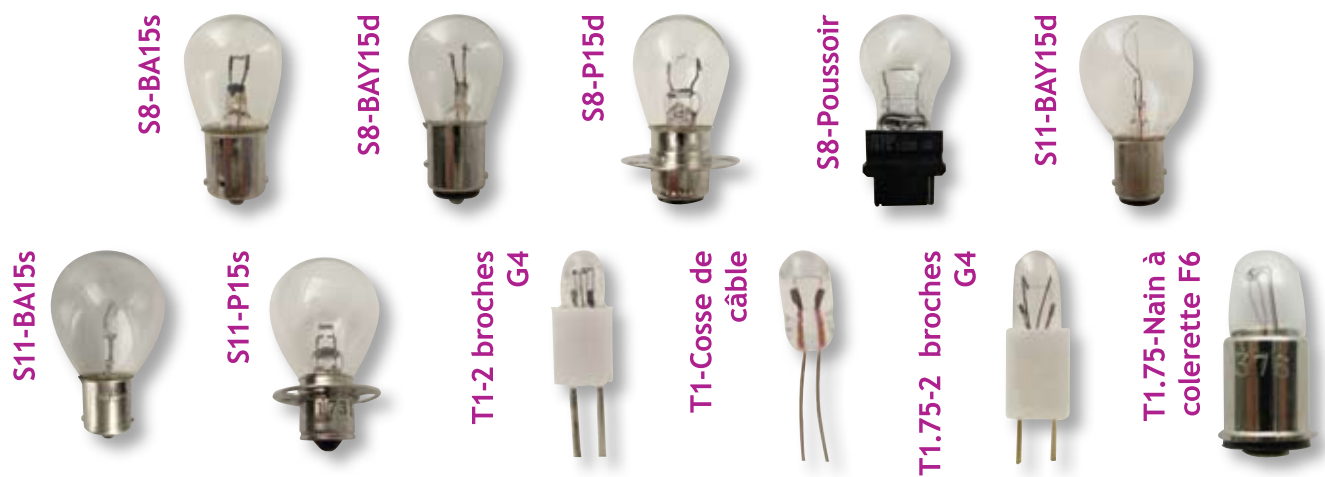

Les images ne sont pas à l'échelle. Toutes les lampes sont claires.

Code de commande	Description	Code de lampe	Forme	Culot	Tension (V)	Ampères (A)	Puissance (W)	Vie moyenne (h)	Diamètre (po) (mm)	HCL (po) (mm)	LHTM (po) (mm)	Qté paq.
------------------	-------------	---------------	-------	-------	-------------	-------------	---------------	-----------------	--------------------	---------------	----------------	----------

S (cont.)

50361	S8/CL/12.8V/1.04A/BA15S/STD	93	S-8	BA15s	12.80	1.040	13	700	1.00 25.40	1.13 28.60	2.01 51.00	10
50412	S8/CL/12.8V/1.44A/BA15s/STD	1141	S-8	BA15s	12.80	1.440	18	500	1.00 25.40	1.25 31.80	2.01 51.00	10
50414	S8/CL/12.8V/2.1A/BA15s/STD	1156	S-8	BA15s	12.80	2.100	27	1200	1.00 25.40	1.25 31.80	2.01 51.00	10
50377	S8/CL/28V/0.51A/BA15S/STD	305	S-8	BA15s	28.00	0.510	14	300	1.00 25.40	1.13 28.60	2.01 51.00	10
10424	S8/CL/28V/0.61A/BA15s/STD	1691	S-8	BA15s	28.00	0.610	17	1000	1.00 25.40	1.13 28.60	2.01 51.00	10
50453	S8/CL/28V/0.64A/BA15s/STD	2232	S-8	BA15s	28.00	0.640	18	2000	1.00 25.40	1.19 30.20	2.01 51.00	10
50721	S8/CL/28V/0.67A/BA15s/STD	307	S-8	BA15s	28.00	0.670	19	300	1.00 25.40	1.13 28.60	2.01 51.00	10
10167	S8/CL/28V/0.77A/BA15s/STD	2233	S-8	BA15s	28.00	0.770	22	2000	1.00 25.40	1.19 30.20	2.01 51.00	10
10136	S8/CL/28V/0.8A/C-2V/BA15s/STD	1665	S-8	BA15s	28.00	0.800	22	1000	1.00 25.40	1.13 28.60	2.01 51.00	10
50428	S8/CL/28V/1.02A/BA15s/STD	1683	S-8	BA15s	28.00	1.020	29	500	1.00 25.40	1.25 31.80	2.01 51.00	10
50415	S8/12.8 14V/2.1 0.59A/DCI/STD	1157	S-8	BAY15d	14.00	0.590	8	5000	1.00 25.40	1.25 31.80	2.01 51.00	10
22037	S-8/6.5V/2.75A/P15d MEDICAL	1630	S-8	P15d	6.50	2.750	18	100	0.59 14.95	1.00 25.40	0.82 20.80	10
13321	S8/CL/12.8V/1.6A/WDG/2P	3155	S-8	Poussoir	12.80	1.600	20	1500	1.00 25.40	1.10 27.90	2.12 53.90	2
13322	S8/CL/12.8V/2.1A/WDG	3156	S-8	Poussoir	12.80	2.100	27	1200	1.00 25.40	1.10 27.90	2.12 53.90	2
13323	S8/CL/12.8 14V/2.1 0.48A/WDG	3157	S-8	Poussoir	14.00	2.100	29	1500	1.00 25.40	1.10 27.90	2.12 53.90	2
13044	10S11/CL/12V/BAY15D	1210M	S-11	BAY15d	12.00	0.833	10	1000	1.37 34.90	1.18 30.00	2.36 60.00	10
13203	18S11/CL/10V/BA15S/STD	S.O.	S-11	BA15s	10.00	1.800	18	1000	1.37 34.90	1.25 31.80	2.36 60.00	10
22045	S11/CL/28V/0.9A/BA15S/STD	309	S-11	BA15s	28.00	0.900	25	300	1.37 34.90	1.25 31.80	2.36 60.00	10
13870	S11/CL/28V/1.29A/1M/BA15S	3011	S-11	BA15s	28.00	1.290	36	1000	1.37 34.90	1.25 31.80	2.36 60.00	10
22024	S11/CL/6.3V/6.6A/P15s/STD	1731	S-11	P15s	6.30	6.600	42	1000	1.37 34.90	0.87 22.20	2.36 60.00	10

T

50701	T1/CL/28V/0.024A/BP/STD	7839	T-1	2 broches G4	28.00	0.024	1	16000	0.13 3.20	0.28 7.11	0.38 9.70	10
22071	T1/CL/5V/0.06A/100M/WT/STD	683	T-1	Cosse de câble	5.00	0.060	0.30	25000	0.13 3.20	0.20 5.07	0.25 6.40	10
50539	T1/CL/0.115A/40M/WT/STD	715	T-1	Cosse de câble	5.00	0.115	1	40000	0.13 3.20	0.20 5.06	0.25 6.40	10
50952	T1.75/CL/12V/0.04A/BP/STD	7371	T-1.75	G4 à 2 broches	12.00	0.040	0	10000	0.21 5.33	0.50 12.70	0.63 15.90	10
50461	T1.75/CL/28V/0.04A/25M/BP/STD	7387	T-1.75	G4 à 2 broches	28.00	0.040	1	25000	0.21 5.33	0.50 12.70	0.63 15.90	10
50491	T1.75/CL/2.47V/.03A/F6/STD	251	T-1.75	Nain à colerette F6	2.47	0.300	0.74	30	0.23 5.84	0.51 12.96	0.63 15.90	10
50697	T1.75/CL/14V/0.08A/40M/F6/STD	382	T-1.75	Nain à colerette F6	14.00	0.080	1	40000	0.23 5.84	0.38 9.65	0.63 15.90	10
50529	T1.75/CL/18V/0.04A/F6/STD	370	T-1.75	Nain à colerette F6	18.00	0.040	1	10000	0.23 5.84	0.38 9.65	0.63 15.90	10
50252	T1.75/CL/28V/0.04A/F6/STD	385	T-1.75	Nain à colerette F6	28.00	0.040	1	10000	0.23 5.84	0.38 9.65	0.63 15.90	10

Cette liste ne comporte qu'une portion de la sélection de lampes miniatures disponibles chez STANDARD. Visitez notre site web pour consulter la sélection complète à www.standardpro.com