


Basic® Cone ☆




1076CH Chrome

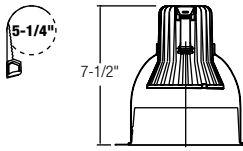

Frame-In Kit	Lamping*	Wattage (non dim/dim)
1001LED Series	900 lms	19W/23W


An economical choice for low budget application is the chrome finish.

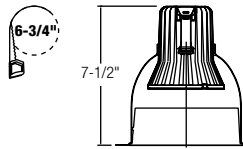

1176CH Chrome

Frame-In Kit	Lamping*	Wattage (non dim/dim)
1101LED Series	900 lms	19W/23W

Premium Die-Cast Step Baffle ☆☆

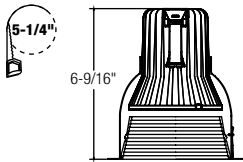

1005BK Black Baffle
1005WB White Baffle




Frame-In Kit	Lamping*	Wattage (non dim/dim)
1001LED Series	900 lms	19W/23W

L56LED09S271 Single Unit		
Ht. to Floor	F.C. At 30" Above Floor	Beam Dia.
8'	27	8
9'	19	9
10'	15	10
Multiple Units		
Ctr. to Ctr.	Footcandles	
	Lrg. Room	Sml. Room
4'	43	31
5'	30	21
6'	20	12

1005WB

Versatile, low brightness downlight. Precision-fitted die-cast aluminum step baffle is finished in black or white and the recessed lamp reduces glare. Anobrite® aluminum reflector.

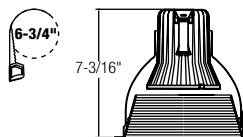

1105BK Black Baffle
1105WB White Baffle

Frame-In Kit	Lamping*	Wattage (non dim/dim)
1101LED Series	900 lms	19W/23W

1101LED09N271 Single Unit		
Ht. to Floor	F.C. At 30" Above Floor	Beam Dia.
8'	27	9
9'	19	10
10'	14	11
Multiple Units		
Ctr. to Ctr.	Footcandles	
	Lrg. Room	Sml. Room
4'	48	34
5'	33	23
6'	22	13

1105WB

*Lumen performance varies by color temperature, driver and trim option. Please reference specification sheets for performance details.