



WHITE



BLACK



SATIN
CHROME

RZR-LED-400

4.00" ULTRA THIN LED RAZOR SERIES - 9W

Product codes

RZR-400-9W-27K-WH : WHITE - 27K

RZR-400-9W-3K-WH : WHITE - 3K

RZR-400-9W-3K-BLK : BLACK - 3K

RZR-400-9W-3K-SC : SATIN CHROME - 3K

RZR-400-9W-4K-WH : WHITE - 4K



RZR-400-9W-4K-BLK : BLACK - 4K

RZR-400-9W-4K-SC : SATIN CHROME - 4K

This ultra-thin recessed unit is IC and AIR TIGHT rated and with its thin profile allows installation in almost any location. It is suitable for wet locations, such as a shower and outdoors in soffits. Included with the unit is a junction box with driver, pressure fit clips and Quick Connect wire connectors for quick and easy installation. The junction box has integrated screw holes to allow the box to be secured to studs or joists, if needed. The maximum number of the 9W fixtures that can be installed with a standard 150W LED dimmer is 16 units. The 27K, 3K & 4K models replace a 600 lumen 50W halogen style bulb. This product is CSA certified in Canada and the US conforms to UL standard 1598 and CSA standard C22.2 NO. 250.0, and includes the following:

The wiring compartment accommodates up to (6) 14 gauge insulated conductors to satisfy luminaire junction box volume requirements.

A complete listing of compatible dimmers may be found in our "Product Knowledge" section of our site. Although this product is AIR-TIGHT rated, some municipalities will require the use of a vapor barrier. Verify local building codes prior to installation.

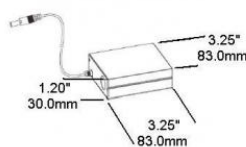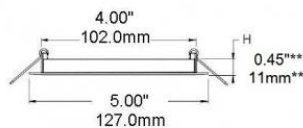

**Height including clip

**Hauteur avec pince

1.08"

27.14mm

Données techniques

Cutting hole	4.25" (108.0 mm)
Beam Angle	107° 1/2
Color Temperature	27K / 3K / 4K
CRI	>80
Dimmable	Y
LED Life	50,000hrs
Mounting Plate	MP/AMP/MPHB 425
Light Output - Lumen	600LM (3K/4K) 575LM(2.7K)
Operating Temperature	-20°c + 40°c