

**THREAD CUTTING FLOORBOARD SCREWS  
VIS AUTOTARAUEUSES POUR PLANCHER**

**225  
Series**



- Flat Head Type 'F'

Used to fasten wood plank, laminated plywood or corrugated aluminium flooring to the supporting steel cross members of trucks and trailers.

**ORDER BY STOCK NUMBER**

Standard Package: 100 Pieces

Stock No.	Size	Driver	Stock No.	Size	Driver
225-792	1/4-20 x 1-1/2	No. 3 Phillips	225-752	1/4-20 x 1-1/2	No. 3 Square
225-793	1/4-20 x 2	No. 3 Phillips	225-753	1/4-20 x 2	No. 3 Square
225-794	1/4-20 x 2-1/2	No. 3 Phillips	225-754	1/4-20 x 2-1/2	No. 3 Square
225-795	1/4-20 x 3	No. 3 Phillips	225-755	1/4-20 x 3	No. 3 Square

**6-LOBE FLOORBOARD SCREWS  
VIS À SIX PANS POUR PLANCHER**

- 6-Lobe Flat Head Tri-Lobular, Phosphate and Oil Finish.



**ORDER BY STOCK NUMBER**

Standard Package: 50 Pieces

Stock No.	Size	Driver	Stock No.	Size	Driver
225-890	1/4-20 x 1	T-30	225-895	1/4-20 x 3	T-30
225-891	1/4-20 x 1-1/4	T-30	225-896	5/16-18 x 1-3/4	T-40
225-892	1/4-20 x 1-1/2	T-30	225-897	5/16-18 x 2	T-40
225-893	1/4-20 x 2	T-30	225-898	5/16-18 x 2-1/2	T-40
225-894	1/4-20 x 2-1/2	T-30			


**DRILL-X<sup>®</sup> SELF-DRILLING TAPPING SCREWS  
VIS TARAUD FORET DRILL-X<sup>®</sup>**

**232  
Series**


- Papco<sup>®</sup> Self-Drilling and Tapping Screws are made of high-quality steel and are specially heat treated.
- The drill point has been incorporated into the screw in the familiar twist drill design.
- These screws drill their own hole - form mating threads - fasten securely and can be used in steel, plastics, composite materials, wood plus various laminates.
- Determine total thickness of the material to be drilled then choose No. 2 or No. 3 point to allow complete drilling.
- Available in Pan Phillips, Pan Socket and Hex Head.

**ORDER BY STOCK NUMBER**

Standard Package: 100 Screws

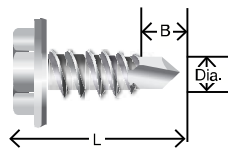

Drill Point length determines maximum Metal thickness drillable.  
No. 2 Point up to .110 Thick      No. 3 Point up to .250 Thick

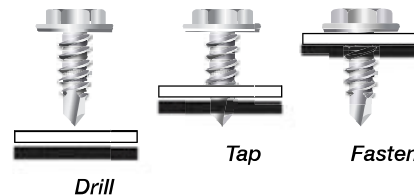

Stock No.	Dia. x (L)	Drill Point	Max-Metal Drillable (B)	Driver	Stock No.	Dia. x (L)	Drill Point	Max-Metal Drillable (B)	Driver
<b>Pan Phillips Head</b>									
232-010	6 x 3/8	No. 2	.090	No. 2	232-016	8 x 1	No. 2	.100	No. 2
232-011	6 x 1/2	No. 2	.090	No. 2	232-020	10 x 1/2	No. 2	.110	No. 2
232-013	8 x 1/2	No. 2	.100	No. 2	232-021	10 x 5/8	No. 3	.175	No. 2
232-014	8 x 5/8	No. 2	.100	No. 2	232-022	10 x 3/4	No. 3	.175	No. 2
232-015	8 x 3/4	No. 2	.100	No. 2	232-024	10 x 1	No. 3	.175	No. 2
<b>Pan Socket Head</b>									
232-030	6 x 3/8	No. 2	.090	No. 2	232-041	8 x 2	No. 2	.100	No. 2
232-031	6 x 1/2	No. 2	.090	No. 2	232-037	10 x 1/2	No. 2	.110	No. 2
232-032	8 x 1/2	No. 2	.100	No. 2	232-038	10 x 5/8	No. 3	.175	No. 2
232-033	8 x 5/8	No. 2	.100	No. 2	232-039	10 x 3/4	No. 3	.175	No. 2
232-034	8 x 3/4	No. 2	.100	No. 2	232-044	10 x 1	No. 2	.175	No. 3
232-035	8 x 1	No. 2	.100	No. 2	232-045	10 x 1-1/4	No. 2	.175	No. 3
232-036	8 x 1-1/2	No. 2	.100	No. 2	232-046	10 x 1-1/2	No. 2	.175	No. 3
232-040	8 x 1-1/4	No. 2	.100	No. 2	232-048	10 x 2	No. 2	.175	No. 3

## DRILL-X® SELF-DRILLING TAPPING SCREWS VIS TARAUD FORET DRILL-X®

ORDER BY STOCK NUMBER

Standard Package: 100 Pieces

Stock No.	Dia. x (L)	Drill Point	Max-Metal Drillable (B)	Driver	Stock No.	Dia. x (L)	Drill Point	Max-Metal Drillable (B)	Driver
Hex Washer Head									
232-070	6 x 1/2	No. 2	.100	3/16	232-086	12 x 3/4	No. 3	.210	5/16
232-071	8 x 1/2	No. 2	.100	1/4	232-087	12 x 1	No. 3	.210	5/16
232-072	8 x 5/8	No. 2	.100	1/4	232-101	12 x 1-1/4	No. 3	.210	5/16
232-073	8 x 3/4	No. 2	.100	1/4	232-088	12 x 1-1/2	No. 3	.210	5/16
232-074	8 x 1	No. 2	.100	1/4	232-089	12 x 2	No. 3	.210	5/16
232-075	8 x 1-1/4	No. 2	.100	1/4	232-090	12 x 2-1/2	No. 3	.210	5/16
232-076	8 x 1-1/2	No. 2	.100	1/4	232-091	12 x 3	No. 3	.210	5/16
232-077	8 x 2	No. 2	.100	1/4	232-092	14 x 3/4	No. 3	.250	3/8
232-078	10 x 1/2	No. 2	.175	5/16	232-093	14 x 1	No. 3	.250	3/8
232-079	10 x 5/8	No. 3	.175	5/16	232-094	14 x 1-1/4	No. 3	.250	3/8
232-080	10 x 3/4	No. 3	.175	5/16	232-095	14 x 1-1/2	No. 3	.250	3/8
232-082	10 x 1	No. 3	.175	5/16	232-097	14 x 2	No. 3	.250	3/8
232-083	10 x 1-1/4	No. 3	.175	5/16	232-098	14 x 2-1/2	No. 3	.250	3/8
232-084	10 x 1-1/2	No. 3	.175	5/16	232-099	14 x 3	No. 3	.250	3/8
232-085	10 x 2	No. 3	.210	5/16	232-100	14 x 4	No. 3	.250	3/8

## MASTER ASSORTMENT

### No. 020-668

- Contains 20 sizes (complete coverage) of Papco® Drill-X® Self-Drilling Tapping Screws in Pan Socket and Hexagon Washer Head.
- Packed in a metal box with high-strength plastic compartments.
- Grease-resistant lid label shows actual size illustrations, measuring chart and retail price codes.



020-668

## 6-LOBE TRIM SCREWS VIS FINITION À SIX PANS

**231**  
Series



Oval Head



Pan Head

- Metric Stainless Steel Tapping Screws
- Used on automotive trim, headlight and tail-light bezels and many other vehicle and appliance applications.
- The six-lobed drive system improves driver tool life, stops cam-out and increases mechanic's efficiency.
- These stainless steel screws have Bright Chromium or Black Oxide finish to conform to original specifications.

ORDER BY STOCK NUMBER

Standard Package: 25 Pieces

Oval Trim Head					Pan Head				
Stock No.	Size	Finish	Driver	O. E. M. No.	Stock No.	Size	Finish	Driver	O. E. M. No.
231-205	4.2 x 20 mm	Chrome	T-15	11504069	231-251	4.2 x 20 mm	Chrome	T-15	11504647
231-206	4.2 x 20 mm	Black	T-15	11504659	231-252	4.2 x 20 mm	Black	T-15	11504655
231-209	4.2 x 30 mm	Chrome	T-15	11504522	231-257	4.2 x 35 mm	Chrome	T-15	11504663
231-210	4.2 x 30 mm	Black	T-15	11504656	231-264	4.2 x 50 mm	Black	T-15	11504774
231-213	4.2 x 40 mm	Chrome	T-15	11504654					
231-219	4.2 x 55 mm	Chrome	T-15	11504664					

Note: 4.2 mm = No. 8 diameter (.164)

## GARAGE ASSORTMENT

### No. 020-070

Contains 70 6-Lobe Oval Head Trim Screws - 6 popular sizes in a clear styrene box.

### No. 020-071

Contains 70 6-Lobe Pan Head Trim Screws - 4 popular sizes in a clear styrene box.



020-070